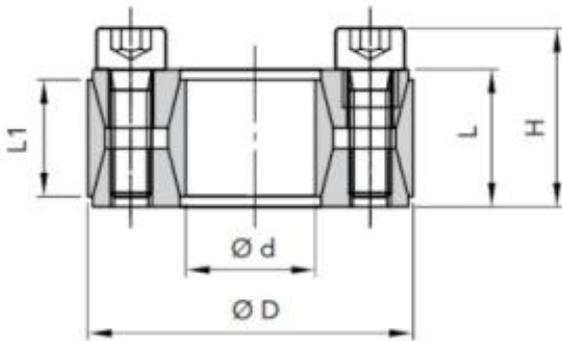


**06400025**

RCK 40 - Not self centering

**2D Technical Drawing**

**Dynamic 3D View**
**Technical Specifications**

Part number (CODE)	06400025
$\varnothing d$ (DD) mm	25
$\varnothing D$ (D) mm	50
L1 (L1) mm	17
L (L) mm	20
H (H) mm	28
Maximum torque Mt (MT) Nm	380
Clamping pressure - Shaft (CPS) N/mm <sup>2</sup>	190
Clamping pressure - Hub (CPH) N/mm <sup>2</sup>	95
Clamping screws DIN 912 MAT. 12.9 - N. (CSN)	9
Clamping screws DIN 912 MAT. 12.9 - Type (CSTY)	M6x18
Clamping screws DIN 912 MAT. 12.9 - Torque (CSTO) Nm	14
Extraction thread - Type (ETT)	M8
Extraction thread - N. (ETN)	3
Weight (WEIGHT) kg	0.25