


coupling socket NPHS-D6-P-G12F

Part number: 8059273

FESTO

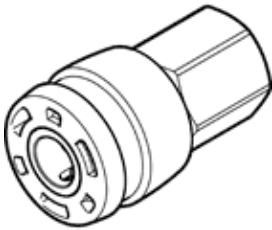

Data sheet

Feature	Value
Operating pressure complete temperature range	-0.95 ... 10 bar
Standard nominal flow rate	1,950 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Product weight	122 g
Pneumatic connection, port 1	Female thread G1/2
Materials note	Conforms to RoHS