



Brand of NTN corporation

## Technical data

### UCFE212-36

Bearing units




Grey cast housing, radial insert ball bearing with socket set screws, seal with slinger

#### KIT CONTENT

UC212-36G2, FE212

#### VISUAL (S)

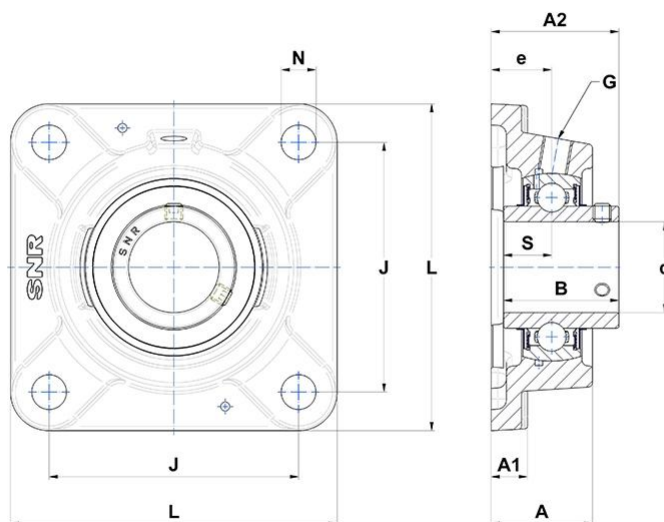

#### PRODUCT DEFINITION

|                                          |          |
|------------------------------------------|----------|
| Brand                                    | SNR      |
| A - Housing height                       | 53,5 mm  |
| A1 - Housing foot height / flange height | 16 mm    |
| A2 - Total height from mounting surface  | 73,7 mm  |
| B - Width of Inner Ring                  | 65,1 mm  |
| d - Shaft diameter                       | 57,15 mm |



**NTN Europe**

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00  
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072  
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

## PRODUCT DEFINITION

|                                                        |         |
|--------------------------------------------------------|---------|
| <b>e - Distance mounting surface to bearing center</b> | 34 mm   |
| <b>G - Grease fitting</b>                              | R1/8"   |
| <b>J - Mounting holes distance</b>                     | 143 mm  |
| <b>L - Housing width / diameter</b>                    | 175 mm  |
| <b>N - Mounting hole dimension</b>                     | 18 mm   |
| <b>S - Distance front side/bearing centre</b>          | 25,4 mm |

## PRODUCT PERFORMANCE

|                                   |             |
|-----------------------------------|-------------|
| <b>C - Dynamic load rating</b>    | 52500000 mN |
| <b>C0 - Static load rating</b>    | 32800000 mN |
| <b>Operating temperature min.</b> | 253,15 °K   |
| <b>Operating temperature max.</b> | 373,15 °K   |

## OTHER FEATURES

|                                                    |          |
|----------------------------------------------------|----------|
| <b>Mass</b>                                        | 5 kg     |
| <b>Recommended tightening torque for set screw</b> | 16.8 N-m |

