

Datasheet


Stock No: 179-2919

Analogue Dial On Delay Timer with Instantaneous contact




Specifications:

- 8 pin plug-in
- Analogue Dial Display
- On-Delay with Instantaneous contact.

RS Stock No		179-2919
Specification		
Supply Voltage		100-240Vac 100-125Vdc
Operating Voltage Range		85~110% rated supply voltage
Display type		Analogue Dial Display
Timing Function		On-Delay with Instantaneous contact.
Timing Range		0.1s – 300h
Contact	Configuration	SPDT (1C) + Instantaneous SPDT (1C)
	Rated Current AC-1	5A @ 250VAC (p.f. =1)
Repetitive Error		±0.3% (FS max.), (±0.3% 10ms max. in range of 1.2s)
Setting Error		±5% (FS max.) ±5ms
Voltage Error		±0.5% (FS max.) (±0.5% ±10ms max. in a range of 1.2s)
Temperature Error		±2% (FS max.) (±2%±10ms max. in a range of 1.2s)
Resetting Time		0.1sec
Insulation resistance		100MW (DC500V)
Vibration Resisance	Destruction	10~55Hz with 0.75mm single amplitude each in 3directions for 2 hours each
	Malfunction	10~55Hz with 0.5mm single amplitude each in 3 directions for 10 minutes each
Shock Resistance	Destruction	30G
	Malfunction	10G
Life Expectancy	Electrical Life	> 10 ⁷
	Mechanical Life	> 10 ⁵ (AC 250V, 5A)
Mounting		8 Plug-in, Panel Mount
Unit Weight		Approx.95g
Certification		

Mounting Dimensions (mm)

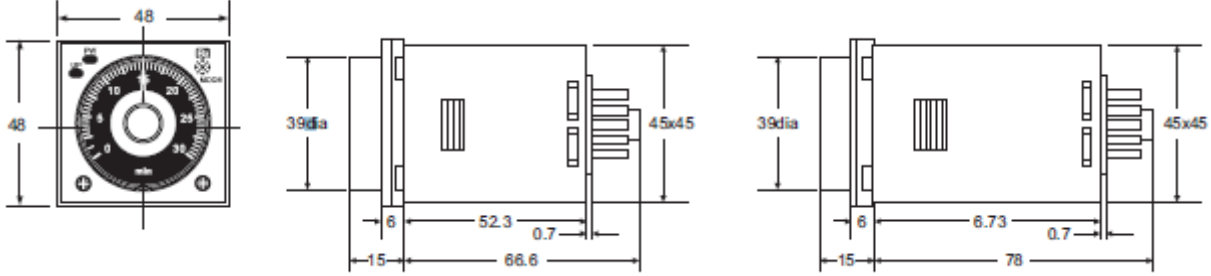

Connection Diagram

