


Datasheet

**RS PRO P 303018 G + MP 3030,
Polyester, 300x300x175mm**

Stock No: 507-999

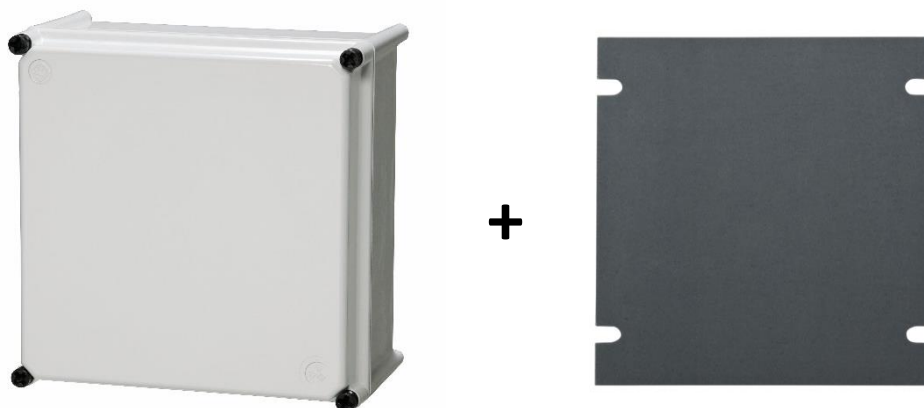

Sample photo

Technical Specifications:

Material	Polyester
Dimensions (LxWxH)	300x300x175mm
Colour	Base: RAL 7036 – light grey Cover: RAL 7036 – light grey
IP Rating	IP 67
IK Rating	IK 10
Electrical insulation	Totally insulated
Flammability Rating	UL 746C 5"

Features & Benefits:

- Halogen free
- Good UV resistance
- Good chemical resistance
- Temperature Range from -50° to $+160^{\circ}$, short term
- Temperature Range from -40° to $+80^{\circ}$, continuous
- Including:

Base, mountingplate, screws for mounting plate/DIN-rail, cover with PUR gasket and polyamide cover screws. The cabinets were designed and tested for wall-/pole mounting in upright position.

Dimensional line drawings

