


Datasheet

RS Pro Female Straight Cable Mount IEC Connector

RS Stock No: 776-9122

Dimensions (mm):

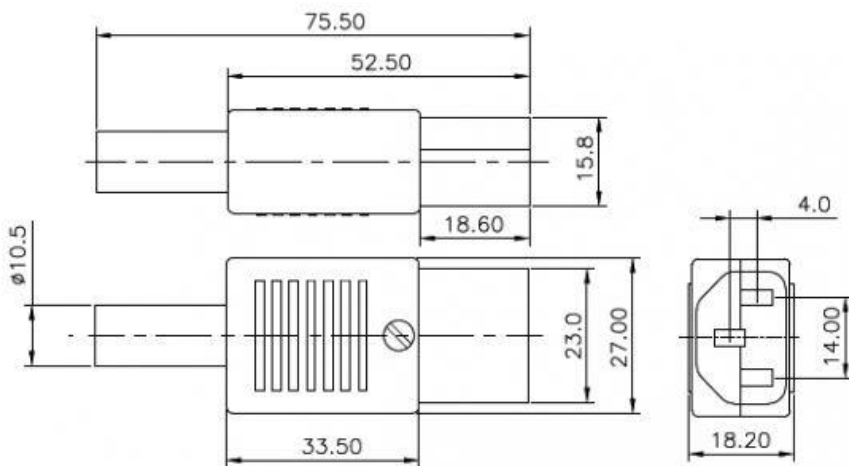

Specifications

Mounting Style	Rewirable
Terminal s	NA
Reference Standard	IEC-60320-1
Permissible Temp With/Without Load	0 to 70°C
Permissible Temp For Soldering	NA
Panel Thickness	NA
Material – Thickness	Copper Alloy, Nickel Plating
Material – Body	Nylon-6, GF20%, V-2
Insulation Resistance @ 500V dc	100M ohm min.
H.V. Break Down Test	2 KV ac for 1 minute
Contact Resistance (Initial)	10m ohm max.
Current & Voltage Rating	10A, 250V ac (VDE)/15A, 250V ac (UL, CSA)
Approvals	UL(C, US), VDE, CE