


Datasheet

Stock No: 402-686

RS Pro 2.54mm Pitch 24 Way

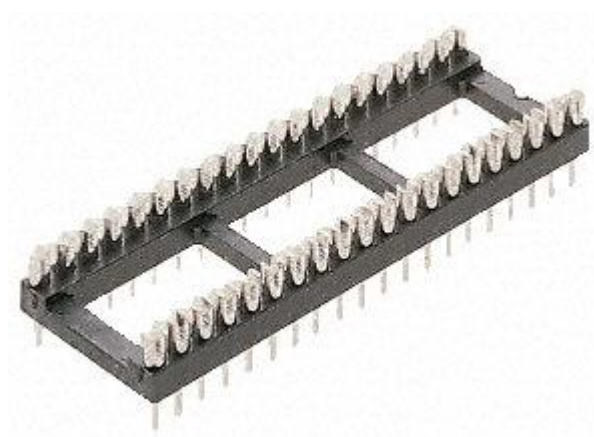

Product Details

Slotted Header

A range of slotted Dual In Line (DIL) headers designed to facilitate building of sub-assemblies or modules for use as a carrier system. May also be used with appropriate DIL sockets to form a plug and socket pair for multi-way connections or directly soldered into PCBs.

Pin spacing : 2.54mm

Operating temperature -55°C → +150°C

Flammability UL 94 V-0

IC Sockets-Components Headers



ENGLISH

Specifications:

| | |
|-------------------------------|-----------------|
| Number of Contacts | 24 |
| Contact Material | Brass |
| Contact Plating | Tin over Nickel |
| Pitch | 2.54mm |
| Termination Method | Solder |
| Mounting Type | Through Hole |
| Housing Material | PBT |
| Current Rating | 1A |
| Depth | 17.66mm |
| Maximum Operating Temperature | +150°C |
| Length | 30.4mm |
| Minimum Operating Temperature | -65°C |