


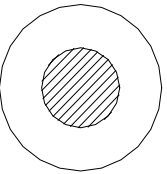

Product Name:	MIL-W-22759/9 24AWG
Product Discription:	MIL-W-22759/9 24AWG
Specification No.:	
Customer's Name:	

Description					
Rated Voltage:		1000V			
Rated Temperature:		200℃			
Reference Standard:		MIL-W-22759/9			
Cross Section					
					
Marking					
No marking on the cable jacket					
Applications					
These wires are ideal for internal wiring of appliances, electronic equipment and other applications.					
Revisions					
Version	Description	Drawn by	Approved by	Date	
0	New document issue	Danniel	Jason	19/05/2015	
Construction					
Conductor		Stranded Sliver plated copper			
Size(AWG)		24			
Construction(±0.008mm)		19/0.127			
Stranded Dia.(mm)Ref.		0.63			
Insulation Material		PTFE			
Insulation Color		ANY COLOR			
Ave Thickness(mm)		0.38			
Insulation Dia.(±0.08mm)		1.37			
Remark: 8776168 Red 8776165 Blue 8776152 Black 8776162 White 8776156 Brown					
Characteristics					Customer Approve
Test Item			Standard Value		Seal & Stamp
Test Material			PTFE(ROHS)		
Insulation resistance(20℃ MΩ*m			1000		
Vol. Tesr(AC.V.60S) (V)			2000		
Flammability Test			VW-1		
Max.DC Resistance(20℃ Ω/km)			77.4(MAX)		
					Signature:
					Date: