

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0687840001](#)
Status: **Active**
Overview: Micro USB
Description: USB Shielded I/O Cable Assembly, USB A-to-Micro-USB B, 1.0m Length, Black, Lead-Free

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-68784-002 \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	68784
Assembly Configuration	Dual Ended Connectors
Connector to Connector	USB Type A-to-Micro-USB Type B
MolexKits	Yes
Overview	<u>Micro USB</u>
Product Name	Micro-USB, USB
UPC	883906173739

Physical

Cable Length	1.0m
Circuits (Loaded)	4, 5
Color - Resin	Black
Gender	Male-Male
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Nickel
Material - Plating Termination	Gold
Material - Resin	PVC
Net Weight	24.800/g
Packaging Type	Bag
Single Ended	No
Waterproof / Dustproof	No
Wire Size AWG	28
Wire/Cable Type	Round


Electrical

Current - Maximum per Contact	1.8A, 1.0A
Impedance	90Ω
Shield Type	Full Shield
Shielded	Yes
Voltage - Maximum	30V AC

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-68784-002
Sales Drawing	SD-68784-001

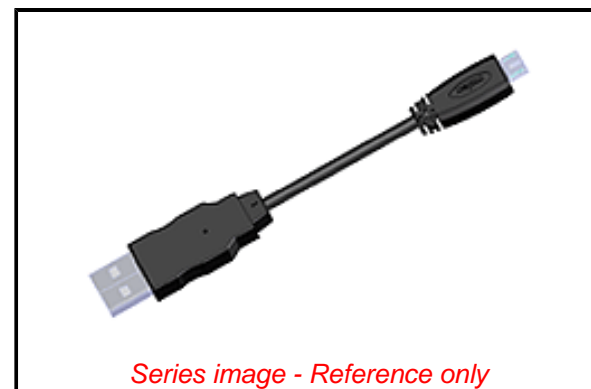

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[68784 Series](#)

Mates With

Micro-USB B-type Receptacles