


Datasheet

RS Pro Feed Through Terminal Block, 1010.2 series, 300 V (CSA), 300 V (UL), 500 V (IEC)

RS Stock No: **872-5596**

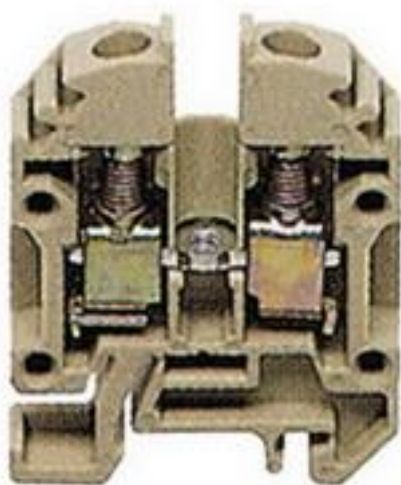

Product Details

RS Pro feed through terminal block in beige colour, has 300 V (CSA), 300 V (UL), 500 V (IEC) voltage rating and 30 A (UL), 32 A (IEC), 40 A (CSA) current rating. The housing is made from nylon 66 for durability. This single level feed-through terminal utilises the Conta-Clip RK screw connection system to provide high contact forces in a small space while ensuring a high level of contact safety. The terminal block meets UL 94-V2 standards.

Features and Benefits

- Screw connection system, 2 connections
- Foot can be snapped on TS 32 and TS 35 DIN rails
- Nylon 66 housing UL 94-V2



ENGLISH

Specifications:

Colour	Beige
Current Rating	40 A (CSA), 32 A (IEC), 30 A (UL)
Maximum Operating Temperature	+105°C
Minimum Operating Temperature	-40°C
Number of Levels	Single
Termination Method	Screw
Voltage Rating	300 V (CSA), 300 V (UL), 500 V (IEC)
Wire Size	22 to 10 AWG
Material	Nylon 66
Standards Met	UL 94V-2, CSA, IEC