

Previously known as: MICROGARD 2500 PLUS - Model 111

Chemical coveralls offering superior protection, durability and breathability.

- **Heightened defenses:** AlphaTec® 2500 PLUS Stitched & Taped - Model 111 chemical-resistant coveralls feature excellent protection from biological agents in line with EN 14126 and ASTM F1671 standards
- **Specialized protection:** This protective suit has type 3-B liquid-tight certification, thanks to its stitched and taped seams, ensuring a stronger and more effective liquid and particle barrier
- **Reduced risks:** Owing to its durable, microporous polypropylene laminate, this protective outer garment also affords breathability, protecting workers from heat stress
- **Increased features:** In addition, this anti-static suit boasts ultra-low linting to reduce the risk of cross contamination in critical areas, and has been tested according to EN 1149-5 standards



Industries

- Life Sciences
- Chemical
- Industrial
- Law Enforcement
- Nuclear


Applications

- Transferring liquids and solids
- Unexpected leakages spills or other releases
- Plant disinfection and sanitization
- Emergency Response
- Spill or leakage cleanup
- Maintenance
- Contaminated Environments


KEY FEATURES & BENEFITS

- **EN 14126 and ASTM F1671 compliance:** Superb protection from biohazards
- **Type 3-B liquid-tight certified:** Safer handling of hazardous liquids
- **Breathable fabric:** Air and water vapor permeable, lowered heat stress

Material Diagram

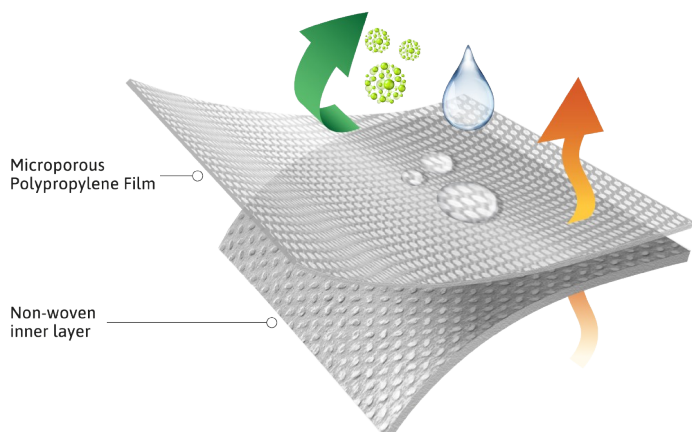

Seam Diagram

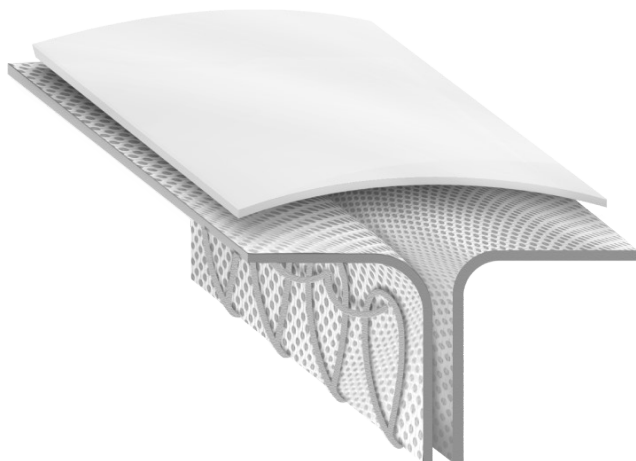

Performance Standards



0598
EN 1073-2
EN 1149-5
EN 14126

EN ISO 13688:2013

Product Information

Product Information	
Available Sizes	S, M, L, XL, 2XL, 3XL, 4XL, 5XL
Color	White
Country Of Origin	China
Packaging Overview	Individually Packed
Product Material	Microporous Polypropylene Laminate non-woven
Product Reference	2500 PLUS - Model 111
Standards Overview	CE CATEGORY III (Type 3-B, Type 4-B, Type 5-B, Type 6-B, EN 1073-2, EN 14126, EN 1149-5)
Seam Type	Stitched and Taped
Shelf Life	5 years

Suit components & accessories

Suit Components and Accessories	
Design Features	Coverall, 3-piece hood, elasticated hood, wrists, waist and ankles. Finger loops and 2-way zip with resealable storm flap.

For additional information visit us at www.ansell.com, or call us at

Europe, Middle East & Africa Region
Ansell Healthcare Europe NV
T: +32 (0) 2 528 74 00

North America Region
Ansell Healthcare Products LLC
T: +1 800 800 0444

Australia
Ansell Limited
T: +61 1800 337 041

Asia Pacific Region
Ansell Global Trading Center
T: +603 8310 6688

Latin America & Caribbean Region
Ansell Commercial Mexico S.A. de C.V.
T: +52 442 248 1544 / 248 3133

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending: www.ansell.com/patentmarking © 2025 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.