



HIGH PERFORMANCE LED HEADTORCH RANGE

Introducing the latest additions to the NightSearcher **LED HEADTORCH** range, the **HT290** and **HT200** are professional products with high performance and ultra robust design. Using the latest in LED technology (Cree XP-G) LED, and a highly efficient large reflector, this unit offers optimum light output over a long distance, covering up to 260m.


Featuring a multimode switch, set to the side, offering rapid one handed mode change (even with gloves) between the 4 light options (high, med, low, SOS).

The adjustable, elasticated head strap features High-Vis reflective strips for additional visibility and the rear battery pack offers a red safety LED, which can be set to static or flashing, for added safety. The lightweight battery packs are also supplied with a high quality, professional pouch, which can be mounted onto belts and bikes.

The **HT290** option is also compatible with larger battery belt packs which are suitable for when longer running times are required.



- 260 metre beam
- 90° Adjustable light head
- 4 modes: High, low, med, flashing
- Rear safety LED—Static or flashing
- Hi-Vis reflective safety strips
- Adjustable, removable head strap
- **HT200 Supplied with:** Battery pouch, extension cord, helmet clips, batteries
- **HT290 Supplied with:** Battery pouch, extension cord, helmet clips, batteries and mains charger
- **Used by:** Utilities, Police, Search & Rescue and Railways
- **Applications:** Maintenance, Overhead line inspection, Track/tunnel inspection, Security patrol

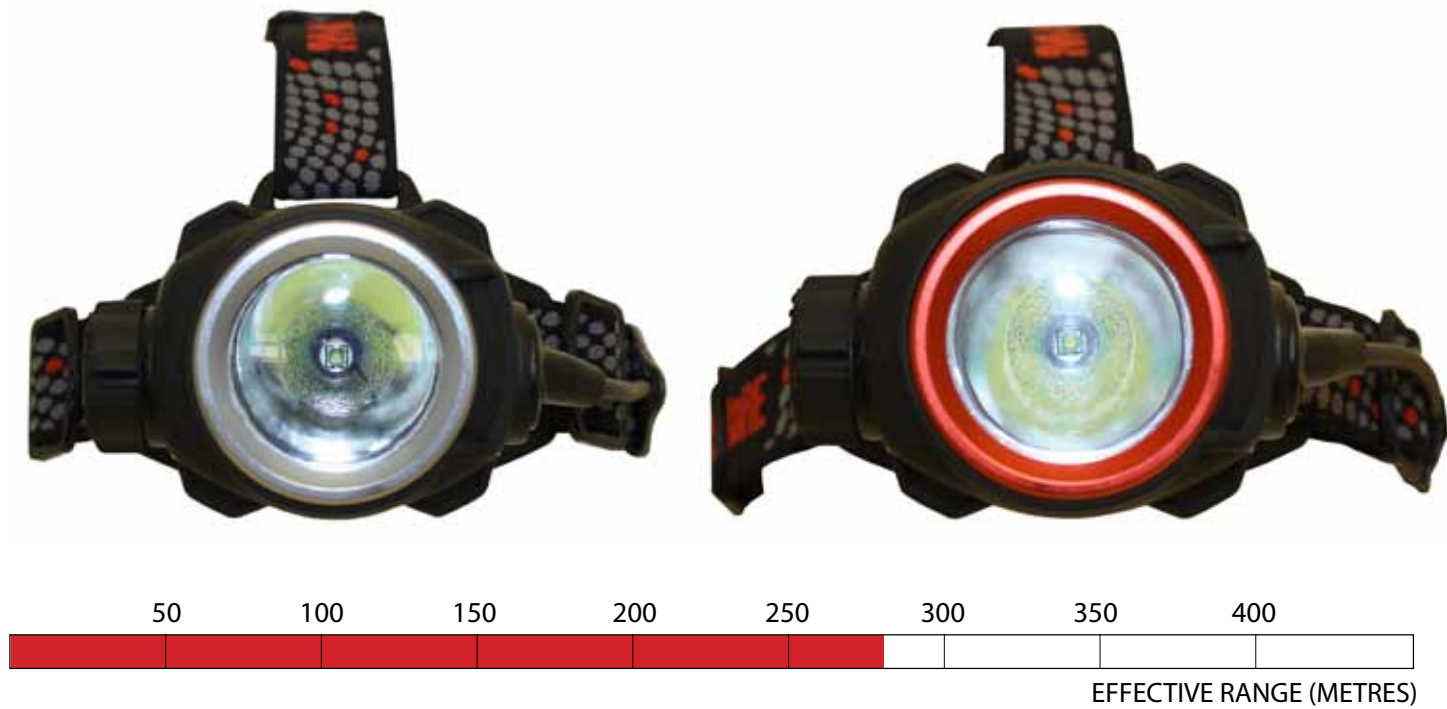

The **HT290** option is supplied with high capacity rechargeable Ni-Mh batteries which offers 3h30–23h runtime, it is also compatible with larger battery belt packs which are suitable for when longer running times are required.



SPECIFICATION

Light output	200 lumens	290 lumens
	50, 20, 20 lumens	85, 55, 55 lumens
Light source	XP-G Cree LED	XP-G Cree LED
Light modes	High, Low, Med, Strobe	High, Low, Med, Strobe
Run time	8h   14h   80h   80h	3h30   15h   20h   23h
Battery	4x AA	4.8V 2200mAh Ni-mh
Charge time		6h
Product size (mm)	HEAD 96 x 67 x 78	96 x 67 x 78
	BATT 31 x 76 x 42	31 x 76 x 42
Product weight (kg)	0.334	0.352
Boxed size (mm)	W150 X H210 X D105	W105 x H85 x D102
Boxed weight (kg)		
Part no.	NSHT200	NSHT290

