


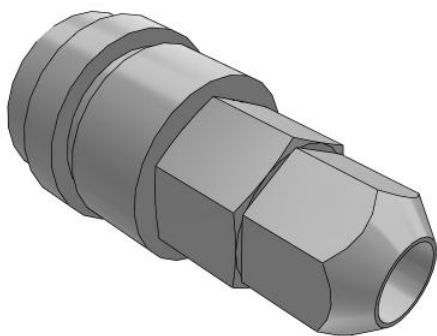

KK*S-*N, S-Couplers, Nut Fitting KK4S-65N


Datasheet

- Nut Fitting.
- Body size: 1/8, 1/4, 1/2.
- Applicable hose O.D.: ø8, ø9, ø10, ø12, ø12.5, ø16.

Standard specifications

Body Size	4 (1/4)
Applicable Hose I.D./O.D.	6.5/10 mm
-	Air, Water
Maximum operating pressure	1.0 MPa
Minimum operating pressure	-90 kPa
Proof pressure	1.5 MPa
Effective Area	39 mm ²
Sealing principle	Electroless nickel plated (copper-free application), With male thread sealant
Weight	0.064 Kg

Dimensions

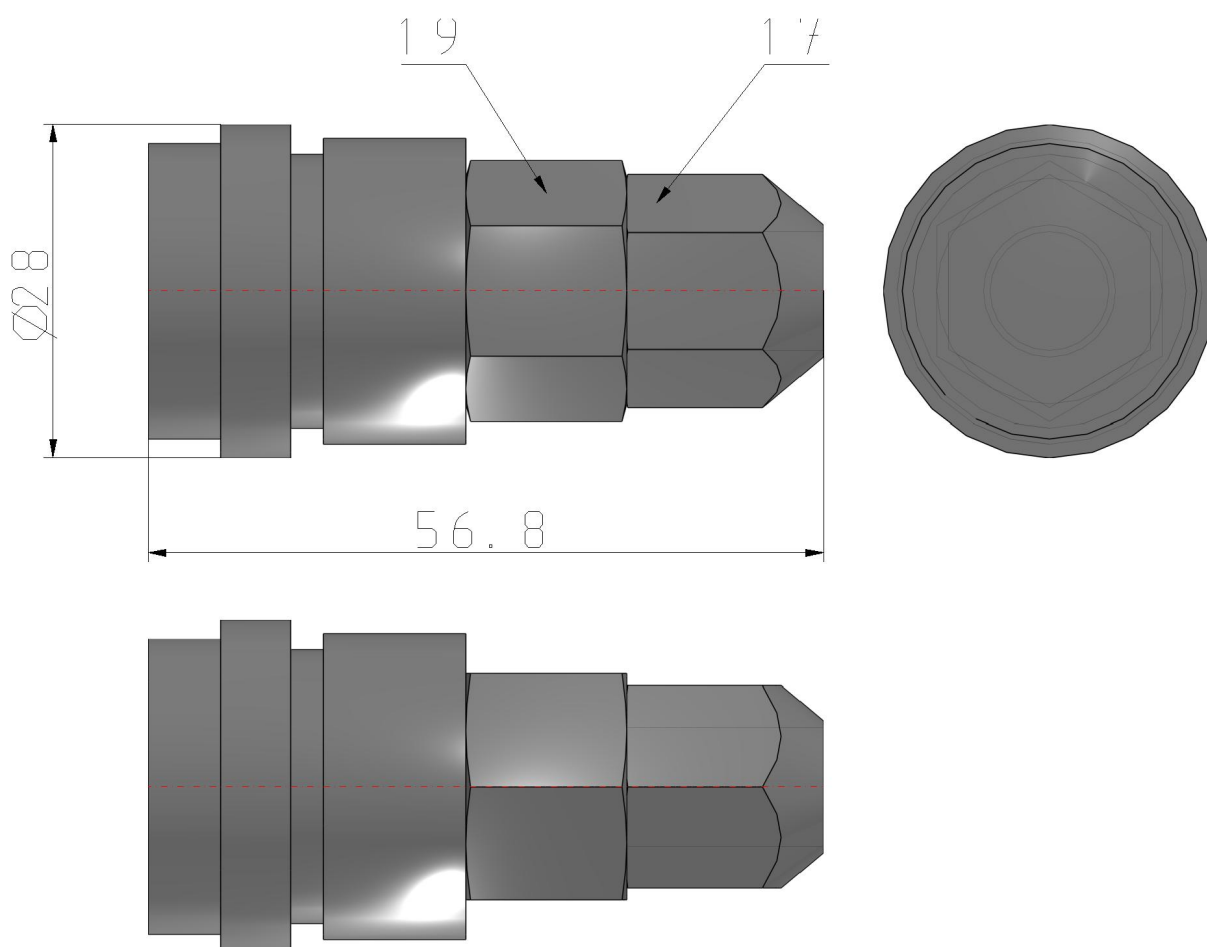

Additional information

Catalogue

[KK-C_EU.pdf](#)