


Datasheet

2m 6-Way Male Moulded Plug to 6-Way Female Moulded Plug DIN Cable Assembly

RS Stock number [463-546](#)

Dimensions (mm)

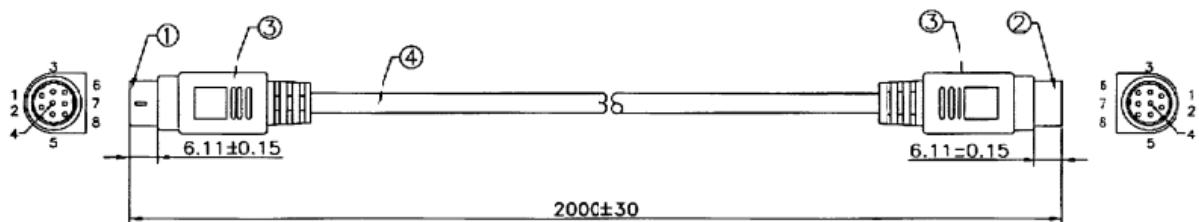

PIN ASSIGNMENT:

MD8 M	1	2	3	4	5	6	7	8	Shell
	Black	White	Red	Yellow	Purple	Blue	Green	Brown	Drain
MD8 F	1	2	3	4	5	6	7	8	Shell

Specifications:

Temperature Range: -25°C To +85°C.
 Current Rating: 1A AC/DC
 Insulation Resistance: 50MΩ Min.
 Voltage Rating: 50V AC/DC
 Withstanding Voltage: 500V AC For 1 Min.

Specifications

- Temperature Range:-25 ° C to +85 ° C
- Current Rating:1A AC/DC
- Insulation Resistance:50M Ω Min
- Voltage Rating: 50V AC/DC
- Withstanding Voltage: 500V AC for 1 min

Material

- Jack Colour: Black
- Moulded PVC Colour: Black
- MD8 Female Contact: Gold Flash, Shell
- Nickel Plated Insulation: Black, PBT UL94V-0
- MD8 Male, Contact: Gold Flash, Shell
- Nickel Plated Insulation: Black, PBT UL94V-0