

1m Premium Certified HDMI 2.0 Cable with Ethernet - Durable High Speed UHD 4K 60Hz HDR - 3ft Rugged M/M HDMI Cord with Aramid Fiber - TPE - Ultra HD Monitors, TVs & Displays

**Product ID:** RHDMM1MPW



This HDMI cable with Ethernet withstands the daily demands of connecting your HDMI devices. Tested to endure strenuous wear and tear, the rugged HDMI cable is a must-have for both business and consumer applications.

This Premium Certified HDMI cable has aramid fiber reinforcement that braces it from the stress of frequent bends. This also lets the cable flex without over-stretching or damaging the core of the cord. <ol>

- Aramid fiber adds strength and durability to the cable
- Insulated conductors reduce friction, provide more flexibility
- EMI protection with aluminum-mylar foil with braided shielding
- TPE cable jacket is more flexible than a standard PVC cable </ol>

The cable is constructed to prevent the connector from separating from the jacket. The extra-long strain relief molding is tested to withstand over 10,000+ bend cycles at a 180 angle.

<ol>

- HDMI gold plated connector with metal shield protects the circuit board from EMI and reinforces the connection point
- Strain relief tested to tolerate over 10,000+ bend cycles at a 180 angle </ol>

Supporting all HDMI 2.0 specifications, this 3ft white HDMI Premium Certified cable supports resolutions up to 4k 60Hz with a bandwidth of up to 18Gbps. The short male to male HDMI cable also supports HDR for higher contrast ratio and vivid colors providing an enriched and enjoyable viewing experience.

RHDMM1MPW is backed by a StarTech.com lifetime warranty and free lifetime technical support.

Note: DuPont and Kevlar are trademarks or registered trademarks of E.I. du Pont de Nemours and Company.

## Certifications, Reports and Compatibility

### Applications

- Connect 4K/Ultra HD displays and devices

### Features

- **PREMIUM HDMI 2.0 CABLE:** Certified HDMI 2.0 with Ethernet w/18Gbps bandwidth; 4K 60Hz (3840x2160), HDR for high contrast ratio, 21:9 cinema aspect ratio, 3D, 32 Ch. multi-stream audio w/1536Hz sampling
- **DURABLE:** Ultra HD high speed HDMI cable w/Kevlar aramid fiber for high tensile (pull) strength for reliability & durability; Tested to withstand 10000+ bend cycles at 180 angle & 5000+ insertions
- **FLEXIBLE CABLE:** TPE jacket absorbs stress of frequent bends protecting the core of the rugged UHD HDMI cord. TPE is non-toxic, halogen free & RoHS certified for environmental sustainability
- **APPLICATIONS:** Ideal for home/office & travel, works w/your laptop for presentations via monitors, projector or large display w/ CEC functions; Compatible w/ HDMI 1.4 1080p HD & previous HDMI versions
- **SPECS:** 1 m (3.3 ft) White HDMI 2.0 HDMI Male to Male 30 AWG Reinforcement: Aramid Fiber Jacket: TPE EMI Shielding Audio Return Channel (ARC) BT.200 colorimetry Lifetime Warranty

---

#### Hardware

Warranty	Lifetime
Connector Plating	Gold
Cable Jacket Material	PVC - Polyvinyl Chloride
Cable Shield Material	Aluminum-Mylar Foil with Braid

---

#### Performance

Audio Specifications	Up to 32 audio channels with 1536Hz sampling rate
----------------------	---------------------------------------------------


---

#### Connector(s)

Connector A	HDMI (19 pin)
	HDMI (19 pin)

---

#### Physical Characteristics

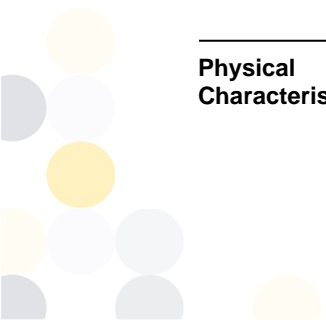

Color	White
Connector Style	Straight
Wire Gauge	30 AWG
Cable Length	39.4 in [100 cm]
Product Length	39.4 in [100 cm]
Product Width	0.7 in [17 mm]
Product Height	0.3 in [7.7 mm]
Weight of Product	1.2 oz [33 g]

---

**Packaging Information**

Package Length	5.9 in [15 cm]
Package Width	7.2 in [18.2 cm]
Package Height	0.8 in [20 mm]
Shipping (Package) Weight	2.8 oz [78 g]

---

**What's in the Box**

Included in Package	HDMI Cable
---------------------	------------

---

*\*Product appearance and specifications are subject to change without notice.*

