

## Features

- Flexible and durable H05VVH3G1.0- pvc cable
- European plug XVIIG-CEE (7)
- Moulded IEC -C17 Connector
- Fully moulded connectors for strength and durability
- Integrated strain relief for connection support and protection

## RS PRO 2.5m Power cable C17, IEC to XVIIG CEE (7) 10A 250 V

RS Stock No.: 0285180



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

## Product Description

RS PRO Power cable in black colour, has C17 connector on one end and a European plug XVIIG CEE (7) connector on the other end and it is 2.5m long current rated for 10A and voltage rated for 250 v. The power cord is designed for environments in which an earthing is not required such as in double insulated devices, for example when audio interference/ noise is caused by the earthing is a concern.

## General Specifications

Connector A	C17, IEC Female – Straight EN60320 /C17
Connector B	CEE (7) XVIIG Male – Straight
Sheath Colour	Black
Material	PVC
Applications	Household Entertainment (TVs, Satellite boxes, routers etc.) Audi / hi-fi equipment, any environment when earthing is not required.

## Mechanical Specifications

Length	2.5m
--------	------

## Electrical Specifications


Power Cord Rating	10 A - 250V
Visual Inspection	100%
Electrical Test	100%
High pot test wire to wire	3.000Vac for 2 sec.
Continuity test	20Aac to line and neutral
Polarity test	no
Skin high pot test	6.000Vac line to skin

## Protection Category

Environmental Conformity	Eu-Directive 2002/96/EC (WEEE)
	Eu-Directive 2003/11/EC (Council Directive 76/769/EEC)
	Eu-Directive 2002/95/EC (RoHS-Compliant)

## Approvals

C17 CONNECTOR	ENEC, CE
XVIIIG CEE (7)	VDE, OVE, CEBEC, KEMA, S, D, N, LCIE, IMQ,
Cable	Harmonised <HAR>

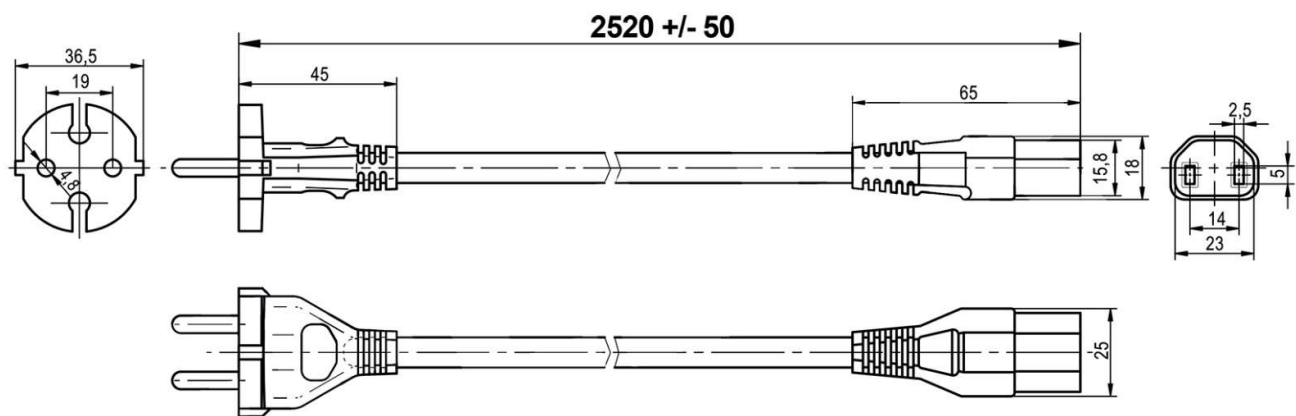

All dimensions in mm