 




## Bracket 40/80





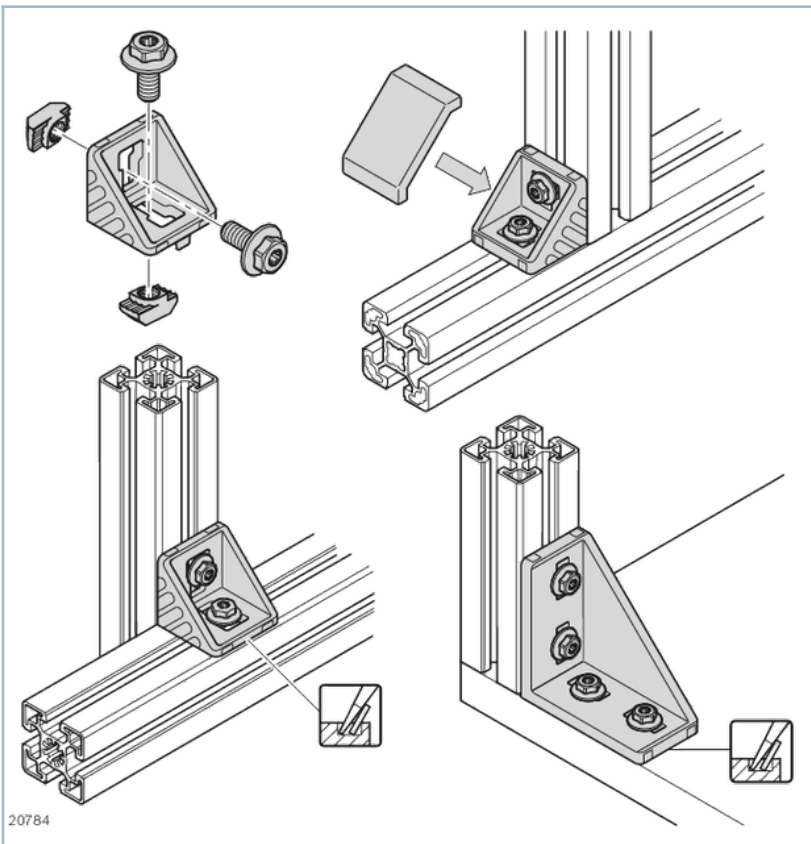


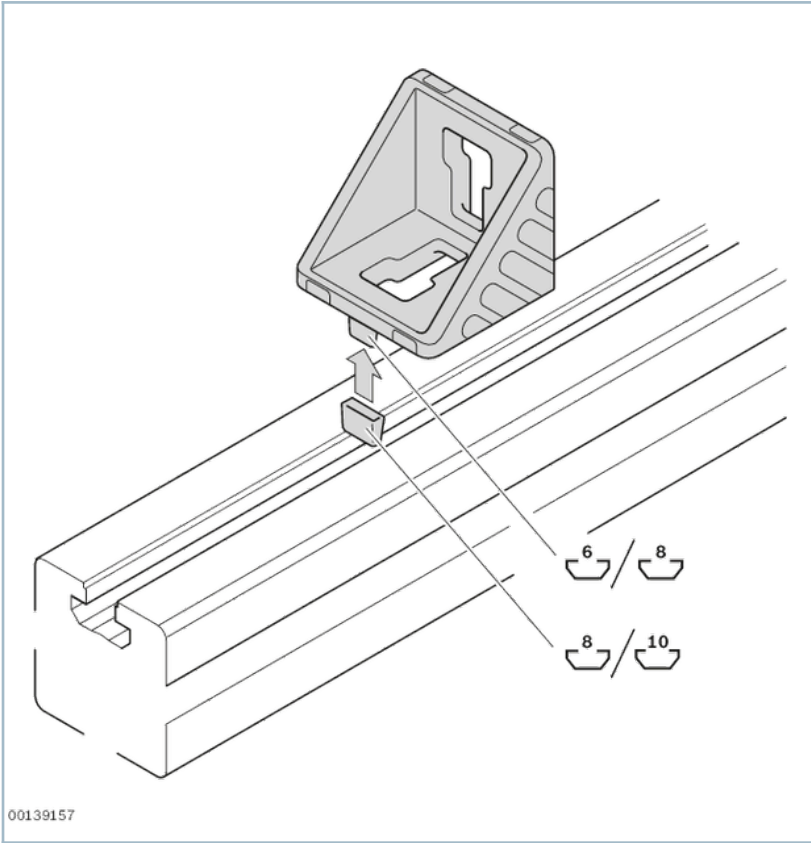

- Brackets with centering lugs for rapid, precise assembly with protection against turning
- Centering lugs can be easily broken off for assembly on plates or at right angles to the slot
- Version *designLINE* with special silver paint (RAL 9006) for an especially high-quality design
- Cover cap to protect from dirt, available in signal gray (RAL 7004) and black ESD (RAL 9005)
- Profile finishing: not required


# Product description





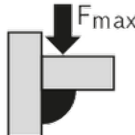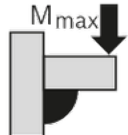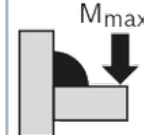

Connection elements, selection criteria

## Technical data

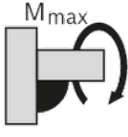
	Groove	ES D	Material entry			
				$F_{max}$	$M_{max}$	$M_{max}$
				N	Nm	Nm
Bracket	10		Bracket: Diecast aluminum, vibratory ground Fastening material: steel; galvanized	6000	180	400
	10		Bracket <i>designLINE</i> : Diecast aluminum; vibratory ground, painted (RAL 9006) Fastening material: steel; galvanized	6000	180	400
	10		Bracket: Diecast aluminum, vibratory ground	6000	180	400
Cover cap for bracket			PP			
			PP			

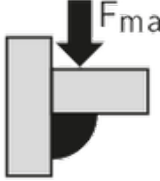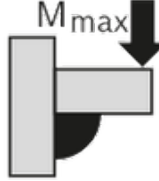
$M_{max}$
Nm
60
60
60

Typ				
40 / 80	6000 N	180 Nm	400 Nm	60 Nm

## Dimensions

### Angle 40/80 with mounting hole plug

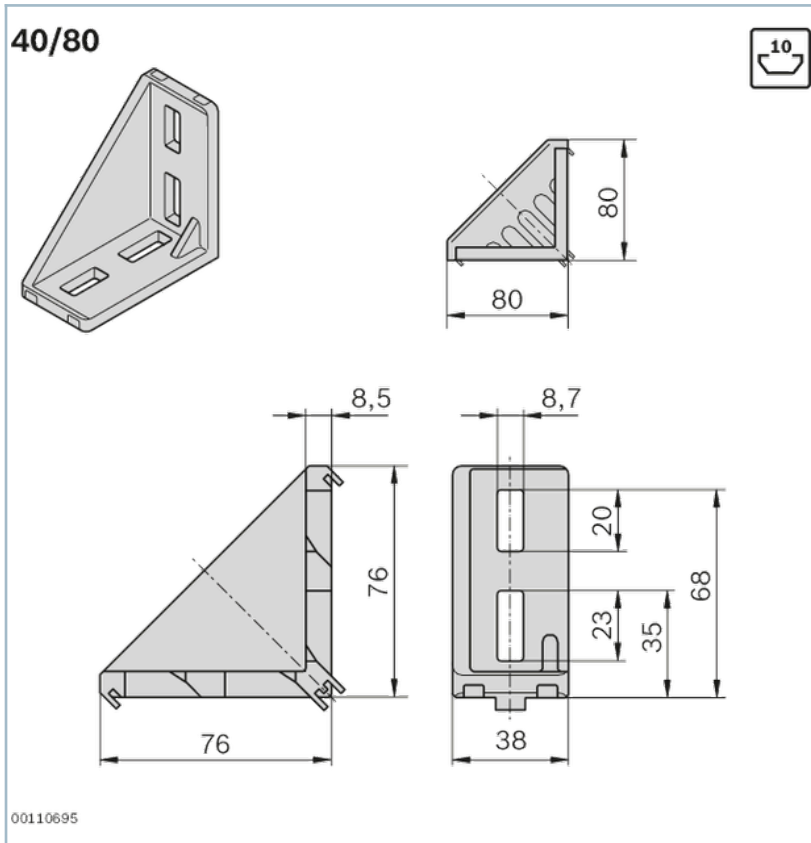

## Accessories


### Recommended accessories

Cover cap for bracket 40/80, signal gray






Cover cap for bracket 40/80, black
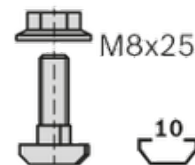
## Delivery notes

FS7



# Ordering codes

	Groove		ESD	FS	No.
Angle 40x80 set (standard)	10			4xFS7	3842529386
Angle 40x80 set design <i>LINE</i>	10			4xFS7	3842551604
Bracket (standard) 40x80	10	20			3842529005
Cover cap for bracket 40/80, signal gray		20			3842548856
Cover cap for bracket 45/180, black		20			3842548857