


**WEE-R** Full Dimensions

Adjustable Locknut Elbow  
24° Flareless / BSPP ORR

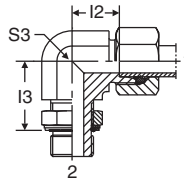


TUBE FITTING PART #	END SIZE		I2 (mm)	I3 (mm)	S3 (mm)	STANDARD Pressure Rating (bar)					
	1 (mm)	2 BSPP				EO			EO-2		
						A3C	71	MS	A3C	71	
WEE04LLR	4	G 1/8A	11	20	11					250	
WEE06LLR	6	G 1/8A	11	20	11					250	
WEE06LR	6	G 1/8A	14	19	14	315				315	
WEE08LR	8	G 1/4A	16	23	14	315				315	
WEE10LR	10	G 1/4A	17	25	19	315				315	
WEE12LR	12	G 3/8A	19	28	19	250				250	
WEE15LR	15	G 1/2A	21	30	22	250				250	
WEE18LR	18	G 1/2A	24	36	27	250				250	
WEE22LR	22	G 3/4A	28	36	30	160				160	
WEE28LR	28	G 1A	31	44	36	160				160	
WEE35LR	35	G 1 1/4A	38	50	50	160				160	
WEE42LR	42	G 1 1/2A	38	52	50	160				160	
WEE06SR	6	G 1/4A	15	23	14	315				315	
WEE08SR	8	G 1/4A	17	27	19	315				315	
WEE10SR	10	G 3/8A	18	29	19	250				250	
WEE12SR	12	G 3/8A	22	29	22	250				250	
WEE16SR	16	G 1/2A	25	36	27	250				250	
WEE20SR	20	G 3/4A	28	39	30	250				250	
WEE25SR	25	G 1A	30	44	36	250				250	
WEE30SR	30	G 1 1/4A	36	49	50	160				160	
WEE38SR	38	G 1 1/2A	34	55	50	160				160	

For EO-2 part number, insert "Z" between size and pressure series.  
Example: WEE04ZLLRA3C

**WEE-M** Full Dimensions

Adjustable Locknut Elbow  
24° Flareless / Metric ORR

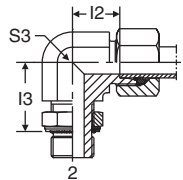

TUBE FITTING PART #	END SIZE		I2 (mm)	I3 (mm)	S3 (mm)	STANDARD Pressure Rating (bar)					
	1 (mm)	2 Metric				EO			EO-2		
						A3C	71	MS	A3C	71	
WEE06LM	6	M10 x 1	14	20	14	315				315	
WEE08LM	8	M12 x 1.5	16	22	14	315				315	
WEE10LM	10	M14 x 1.5	17	24	19	315				315	
WEE12LM	12	M16 x 1.5	19	25	19	315				315	
WEE15LM	15	M18 x 1.5	21	31	22	315				315	
WEE18LM	18	M22 x 1.5	24	33	27	250				250	
WEE22LM27X2	22	M27 x 2	28	36	30	160				160	
WEE28LM	28	M33 x 2	31	39	36	160				160	
WEE35LM	35	M42 x 2	38	49	50	160				160	
WEE42LM	42	M48 x 2	38	50	50	160				160	
WEE06SM	6	M12 x 1.5	15	22	14	315				315	
WEE08SM	8	M14 x 1.5	17	26	19	315				315	
WEE10SM	10	M16 x 1.5	18	27	19	315				315	
WEE12SM	12	M18 x 1.5	22	31	22	315				315	
WEE16SM	16	M22 x 1.5	25	36	27	250				250	
WEE20SM	20	M27 x 2	28	39	30	250				250	
WEE25SM	25	M33 x 2	30	44	36	160				160	
WEE30SM	30	M42 x 2	36	51	50	160				160	
WEE38SM	38	M48 x 2	34	54	50	160				160	

For EO-2 part number, insert "Z" between size and pressure series.  
Example: WEE06ZLMA3C

- How to Order
- Specs
- Assembly / Installation
- Reference

