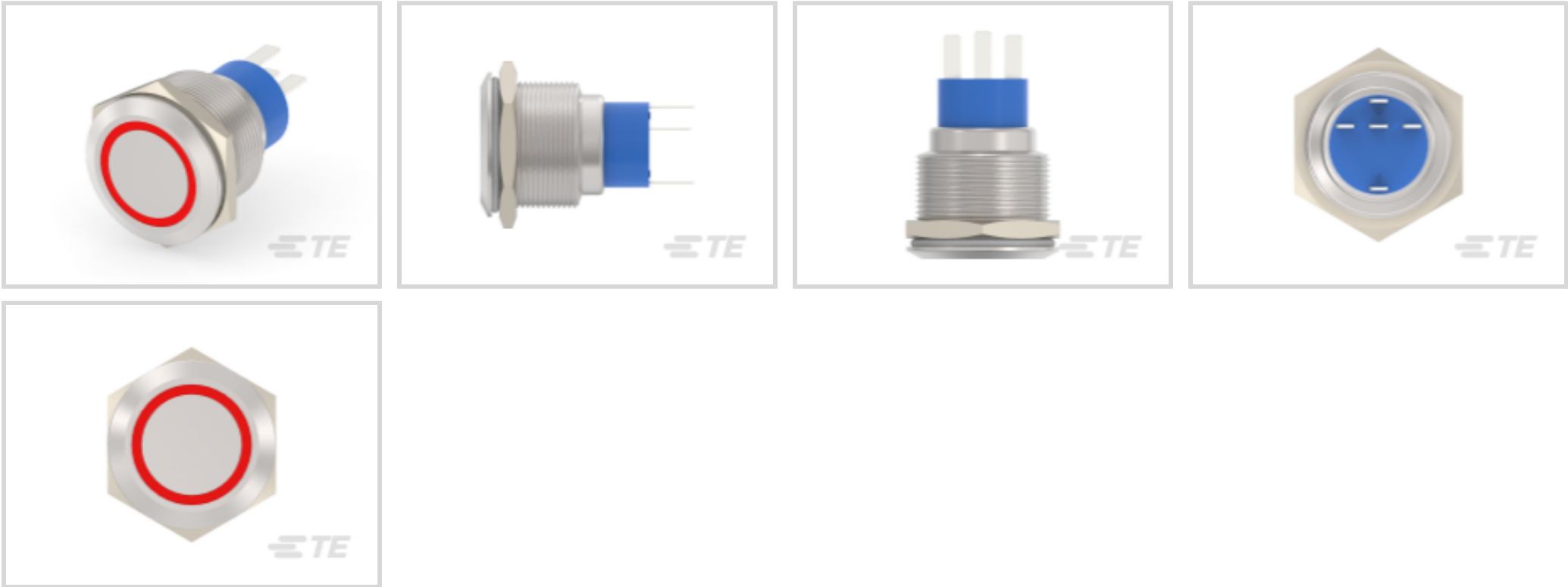




Switches > Push Button Switches



Push Button Switch Product Type: **Anti-Vandal Switch**
Configuration (Pole-Throw): **Single Pole - Single Throw**
Number of Actuators: **Single**
Actuator Profile: **Flush**
Bushing Style: **Threaded**

Features

Product Type Features

Switch Connection Type	Wire Lugs
Push Button Switch Product Type	Anti-Vandal Switch
Illuminated	With
Actuator Style	Round Actuator

Configuration Features

Configuration (Pole-Throw)	Single Pole - Single Throw
Number of Actuators	Single
Snap Action	Without
Support Bracket	Without
Switch Feedback Type	Auditory
Operating Function	Momentary

Electrical Characteristics

Contact Current Rating	3 A
Operating Voltage Range	250 VAC



Body Features

Case Material	PBT
Product Orientation	Vertical
Actuator Force	255 g[9 oz]
Actuator Profile	Flush
Bushing Style	Threaded

Contact Features

Switch Contact Plating Material	Silver
---------------------------------	--------

Housing Features

Process Sealed	Yes
----------------	-----

Dimensions

	22 in
--	-------

Industry Standards

IP Rating	IP67
-----------	------

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2024 (241) SVHC > Threshold: Pb (4% in Component Part) Article Safe Usage Statements: Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

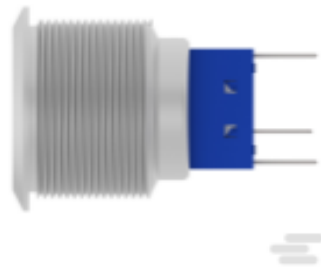
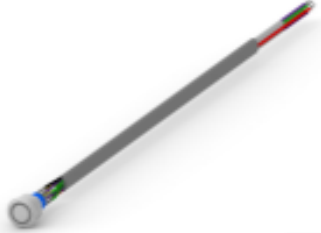
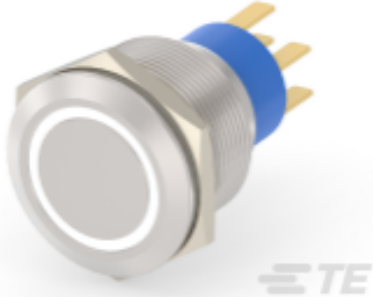
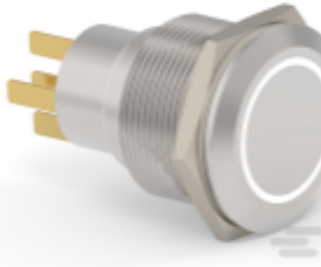
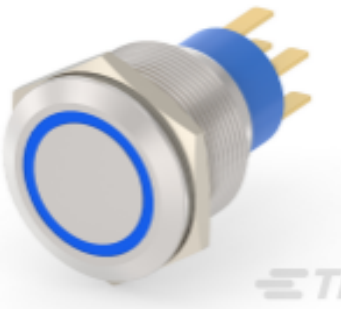
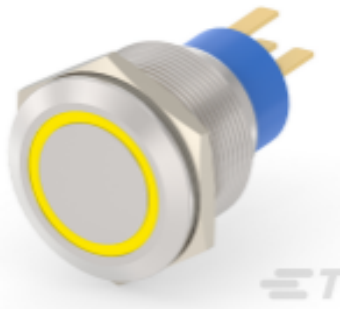
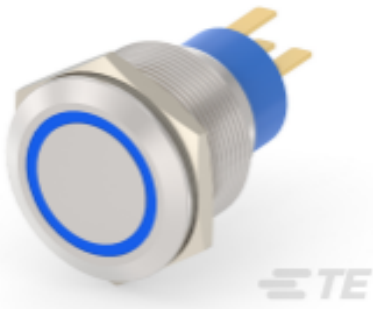
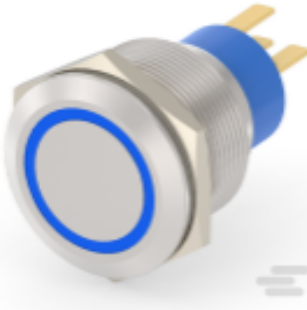
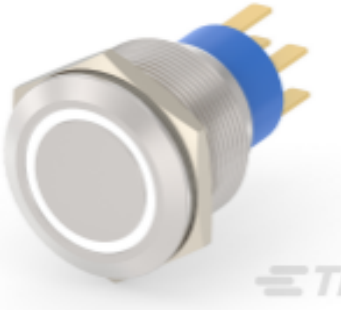
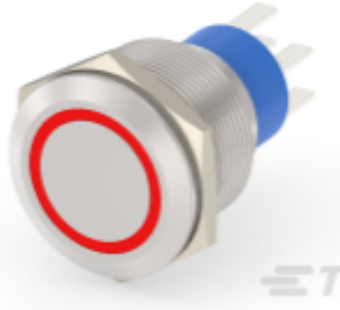
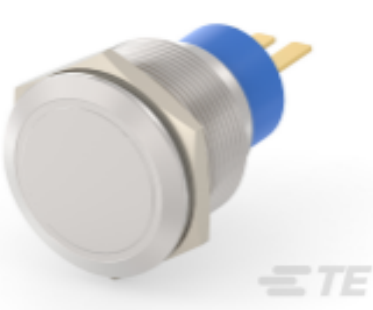
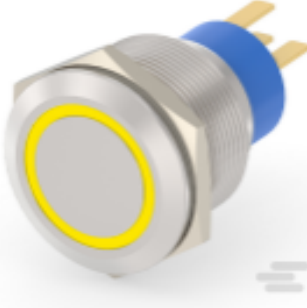
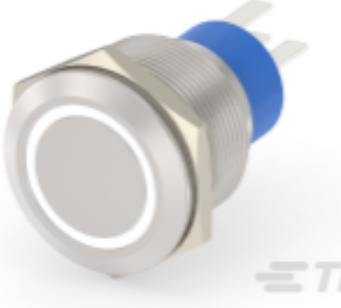
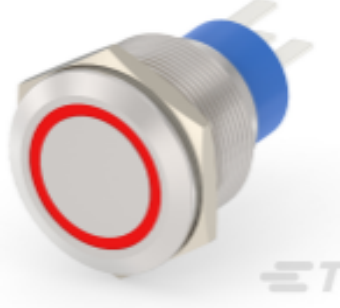
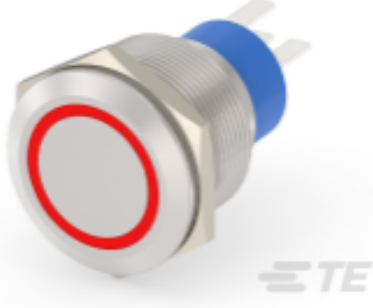
Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent



chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

 TE Part # 2317570-4 AV22 SPM 3A MOVING RING R&B 24V	 TE Part # 4-2317570-5 AV22 DPM 3A MOVING RING R&B 24V FL	 TE Part # 4-2317570-7 AV22 DPM 3A MOVING RING R&Y 24V FL	 TE Part # 6-2213772-4 AV22 DPL 0.4VA MOVE RING LED WHITE 24V
 TE Part # 2-2213772-4 AV22 SPL 0.4VA MOVE RING LED WHITE 24V	 TE Part # 7-2213772-8 AV22 DPL 0.4VA MOVE RING LED BLUE 12V	 TE Part # 1-2213772-2 AV22 SPM 0.4VA MOVE RING LED YELLOW 24V	 TE Part # 2-2213772-0 AV22 SPM 0.4VA MOVE RING LED BLUE 24V
 TE Part # 3-2213772-8 AV22 SPL 0.4VA MOVE RING LED BLUE 12V	 TE Part # 6-2213772-2 AV22 DPL 0.4VA MOVE RING LED WHITE 12V	 TE Part # 4-2213772-7 AV22 DPM 3A MOVE RING LED RED 24V	 TE Part # 2213771-4 AV22 SPL 0.4VA NO LED
 TE Part # 1-2213772-0 AV22 SPM 0.4VA MOVE RING LED YELLOW 12V	 TE Part # 2213772-1 AV22 SPM 3A MOVE RING LED WHITE 12V	 TE Part # 2-2213772-7 AV22 SPL 3A MOVE RING LED RED 24V	 TE Part # 2-2213772-5 AV22 SPL 3A MOVE RING LED RED 12V





TE Part # 2342836-6
AVC22L FLAT S16 RED R 500MM/1X6



TE Part # 2342836-7
AVC22M FLAT AIO RGB R 500MM/1X6



TE Part # 2342837-4
AVC22L FLAT S04 RED RL 500MM/1X6



TE Part # 2342837-7
AVC22M FLAT AIO RGB RL 500MM /1X6

Also in the Series |

Alcoswitch AV22



Anti-Vandal Switches(124)

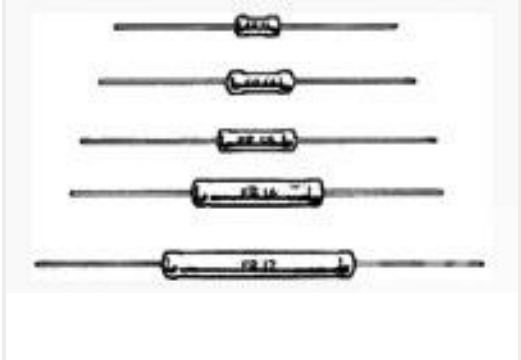


Push Button Switches(124)


Customers Also Bought



TE Part #1SNA168556R0500
FU633



TE Part #1-1623750-8
ER58 2K2 5% AMMO

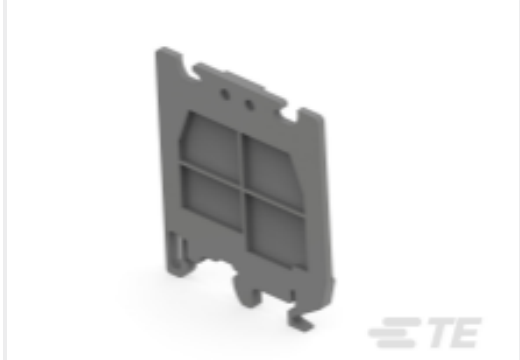


TE Part #1SNA114825R0500
SCFM6




TE Part #1SNK900607R0000
LH-R1



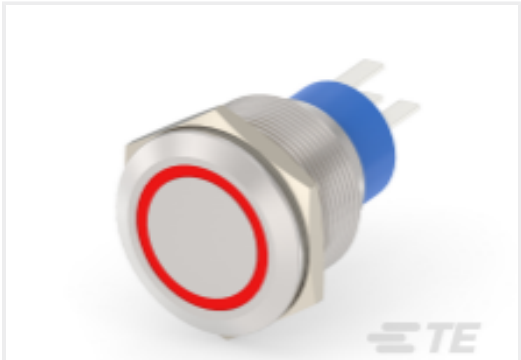TE Part #1SNA113548R2600
PC6-10



 TE Part #2-2213772-5
AV22 SPL 3A MOVE RING LED RED 12V



TE Part #1SNA114434R0500
FEMR10



TE Part #3-2213772-3
AV22 SPL 3A MOVE RING LED GREEN 12V



TE Part #1SNA399719R1000
PEAD



TE Part #6-1393234-7
RP421012



Documents

Product Drawings

AV22 SPM 3A MOVE RING LED RED 12V

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_2213772-5_A.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_2213772-5_A.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_2213772-5_A.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

ALCOSWITCH Anti-Vandal Switch

English

Agency Approvals

UL Report

English