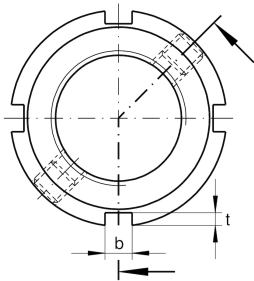
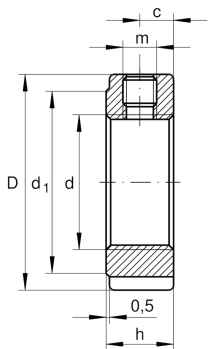
**ZMA50/75** **Precision locknut**

Precision locknuts ZMA, locking pegs, radially arranged, heavy series

Technical information**Main Dimensions & Performance Data**

d	M50X1,5	Thread
D	75 mm	Outside diameter
h	25 mm	Height
M _A	15 Nm	Mounting torque set screw
F _{aB}	415,000 N	Breaking load, axial
M _L	130 Nm	Breakawag
M _{AL}	85 Nm	Mounting torque reference
M _M	4.89 kg*cm ²	Mass moment of inertia
≈m	0.462 kg	Weight

Dimensions

d ₁	68 mm	Plant diameter outside
t	2.5 mm	Hight retaining slot
b	6 mm	Width retaining slot
c	12.5 mm	Distance bore
m	M8	Threaded - threaded pin