



Technical data

HK1522ZWD

Drawn cup needle roller bearings, opened end

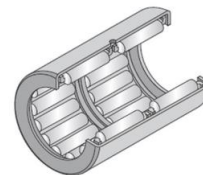

VISUAL (S)

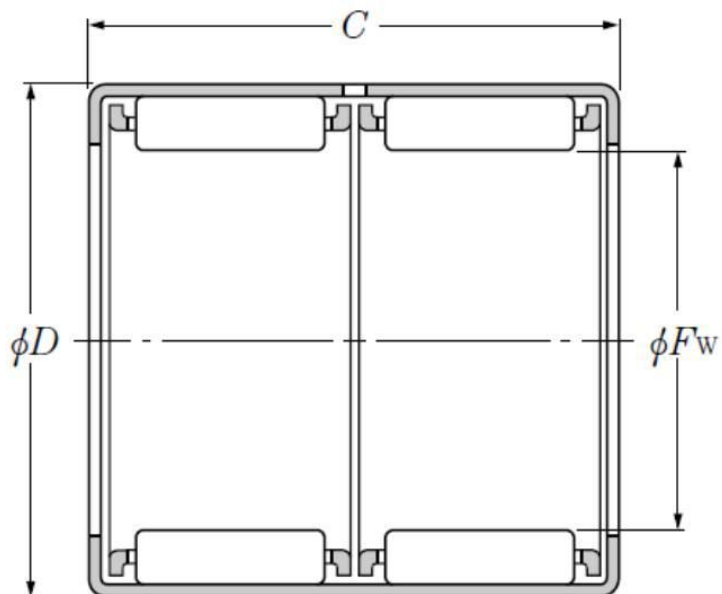

PRODUCT DEFINITION

Brand	NTN
Fw - Under rollers diameter	15 mm
D - External diameter	21 mm
C - Width of bearing, drawn cup or outer ring	22 mm
Lubrication hole on outer ring	Oui/Yes
k - Hole diameter	2,5 mm
Inner ring reference	IR12X15X22.5
Mass	0,02 kg



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

HK1522ZWD

Drawn cup needle roller bearings, opened end

PRODUCT PERFORMANCE

Cr - Dynamic load rating	12,9 kN
C0r - Static load rating	18,2 kN
N lim - Grease lubrication limit speed	11000 tr/min
N lim - Oil lubrication limit speed	16000 tr/min
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	120 °C

ESHOPDONOTDISPLAY

Tracepart	Oui/Yes
Reference	HK1522ZWD
Image	NRBHK_ZWD_1.jpg, NRBHK_ZWD_3.jpg
Rolling element material	Acier 100Cr6



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15