

L 13-10 125-EC


1300 watt angle grinder with brushless motor,
125 mm

Order no. 495255

GTIN 4030293224391



- + Brushless motor with greater efficiency and a longer service life
- + Microprocessor control with soft start, restart protection after power failure, temperature monitoring, overload protection, CDC-electronic feedback control
- + Anti-Kickback - this shuts down the motor on the disc being blocked
- + Perfect dust protection thanks to removable protective metal grille
- + Extremely streamlined handle section for perfect handling
- + More ergonomic handling due to inclined side handle
- + Extremely light and handy
- + Tool-free adjustment of safety guard
- + Spindle lock
- + This universal angle grinder is suited for steel/metal surface finishing, for work on the site/renovation as well as for vehicle bodywork and construction firms
- + Side handgrip

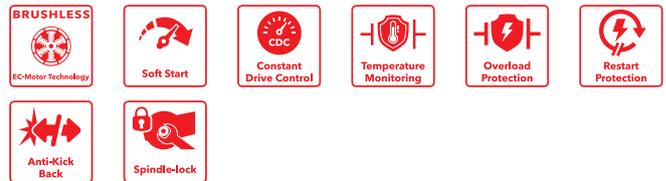

Technical data

Power consumption

1300 W

Standard equipment

- 1 Sanding guard (436860)
- 1 Clamping flange (335282)
- 1 Clamping nut M 14 (100080)
- 1 Face pin spanner (100110)
- 1 Handle (450774)