




Clamp Connectors Swivelling Connecting Clamps





General features

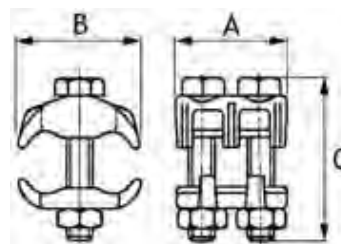
✓ On request, clamp connectors can be fitted with bronze screws.

In this case, please suffix the PN with the letter « B ». (eg. RG1-25B).





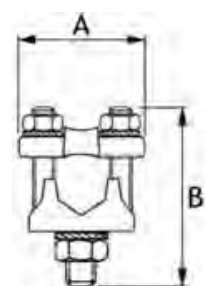

Clamp connectors

 mm ²	 Item code	 Part No.		Bolts	A	B	C
4 - 30	7601001	RG1-25	50	1 x M 6	18	22	24
4 - 30	7601002	RG1-25B	50	1 x M 6	18	22	24
4 - 16	7601011	RG2-16	50	2 x M 5	21	19	29
4 - 16	7601012	RG2-16B	50	2 x M 5	21	19	29
4 - 35	7601021	RG2-35	25	2 x M 5	24	24	29
4 - 35	7601022	RG2-35B	25	2 x M 5	24	24	29
4 - 50	7601031	RG2-50	25	2 x M 6	28	29	34
4 - 50	7601032	RG2-50B	25	2 x M 6	28	29	34
16 - 95	7601041	RG2-95	10	2 x M 8	36	39	46
16 - 95	7601042	RG2-95B	10	2 x M 8	36	39	46
30 - 150	7601051	RG2-150	10	2 x M 8	37	48	51
30 - 150	7601052	RG2-150B	10	2 x M 8	37	48	51



Swivelling connecting clamps

 mm ²	 Item code	 Part No.		intensity (A)	Bolts	B	C
10 - 95	7603301	P095	6	160	2 x M 6	33	50
16 - 150	7603311	P0150	6	250	2 x M 8	45	64
35 - 240	7603321	P0240	3	400	2 x M 10	50	78