

Data sheet article 84V410


Stainless steel tubular cable lug

heat resistant up to 400° C
for aggressive environmental factors
ring type

cross section 25mm², Bolt size M10



A: dimensions	d ₁ :	7,0	mm
	d ₄ :	10,0	mm
	l:	34,0	mm
	a:	15,0	mm
	b:	18,0	mm
	d ₂ :	10,5	mm

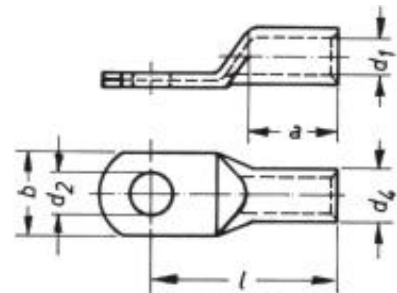

B: Material specification:

1 general

1.1 material
V4A (1.4571) (AISI 316 Ti)

2 condition

2.1 surface

2.1.1 smooth, brightly, evenly, no tears, scoring, folds, blisters, no other defects.