


Optional Parts

Mounting Poles & Brackets (mm)



PART No.	MODEL	PART No.	MODEL	PART No.	MODEL	PART No.	MODEL	PART No.	MODEL
SZ-70L	LME-W	SZ-60L	LEL	SZ-50L	LHE-A, LUT	SZ-40L	KUS	SZ-30L	KUS, KX, LGE, PES, PS,
SZ-80L	LCE-W	SZ-60T	LES-AW	SZ-50T		SZ-40T		SZ-30T	SKH-A, SKH-EA, RH-A, RU

Mounting Brackets (mm)

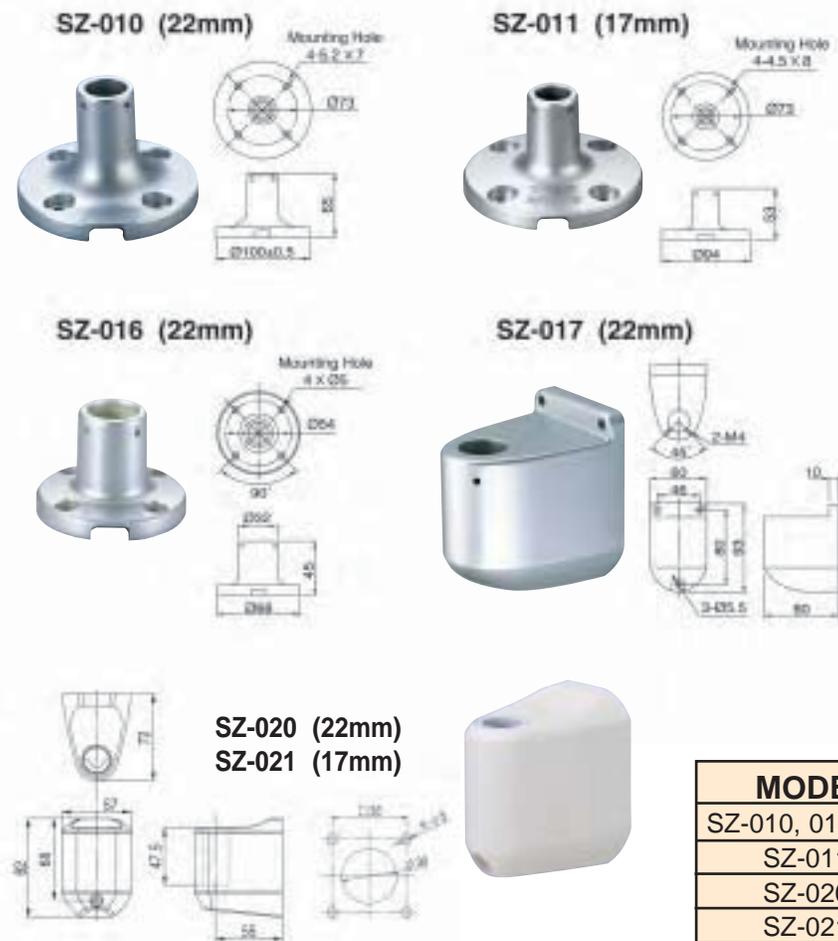

Rubber Gaskets (mm)



MODEL	PRODUCT
SZ-200A	KX-T, RHB-A, SKH-EA
SZ-210	PES, PS, PSF, RU




MODEL	PRODUCT
SZ-010, 016, 017	LME, LME-L, RUP, SE-T, ST, STPB
SZ-011	LCE, LE-P, LES-A
SZ-020	LME
SZ-021	LCE, LE-P, LES-A
SZ-903	LCE, LE-P, LES-A, ME, MEL, MES, MT
SZ-904	LME-L, RUP, SE-T, ST, STPB

Mounting Brackets (mm)

SZ-012



(Pole is not included)

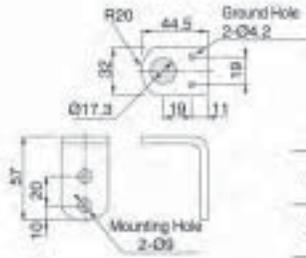


MODEL	PRODUCT
SZ-012	LCE, LE-P, LES-A

SZ-013



(Pole is not included)

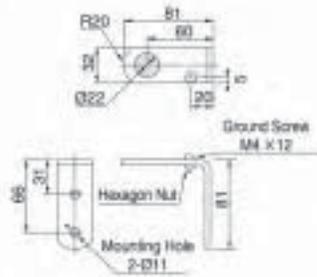

MODEL	PRODUCT
SZ-013	LME-L, ME, MEL, MES, MT, AUP, SE-T, ST, STPB

SZ-007



MODEL	PRODUCT
SZ-007	KJS, KJS, KX, LGE, LHE-A, LME, LU PES, PS, RH-A, RU, SKH-A, SKH-EA

SZ-008



MODEL	PRODUCT
SZ-008	KJ, KJT, KP, RT

Replacement Bulbs

TYPE	BULB No.	WATTAGE	PART No.	
G18/BA15S	5	12V15W	LMP-0071	
	6	24V20W	LMP-0072	
	9	12V10W	LMP-0099	
	10	24V10W	LMP-0100	
	11	12V5W	LMP-0093	
T20/E12	7	12V10W	LMP-0097	
	8	12V5W	LMP-0091	
	12	30V10W	LMP-0098	
	13	24V5W	LMP-0060	
	14	110V10W	LMP-0094	
	15	140V10W	LMP-0086	
	16	140V5W	LMP-0061	
	17	110V15W	LMP-0119	
	18	220V15W	LMP-0120	
	19	240V10W	LMP-0053	
G14/BA9S	20	12V6W	LMP-0116	
	21	24V6W	LMP-0117	
T10/E10	22	140V3W	LMP-0121	
	23	140V5W	LMP-0125	
	24	110V5W	LMP-0110	
	25	240V5W	LMP-0112	
	27	12V0.11A	LMP-0113	
	28	24V0.11A	LMP-0108	
	T20/BA15D	39	28V11W	LMP-0228
		40	110V12W	LMP-0211
41		250V11W	LMP-0225	
49	140V13W	LMP-0214		

TYPE	BULB No.	WATTAGE	PART No.
T20/BA15D	50	28V20W	LMP-0328
	52	140V20W	LMP-0314
	53	250V20W	LMP-0325
RP35/BA15S	56	12V35W	LMP-0004
	57	24V35W	LMP-0005
RP35/BA15D	60	120V40W	LMP-0092
	61	240V30W	LMP-0062
	62	48V35W	LMP-0008
	63	220V30W	LMP-0007
T10/BA15S	70	12V55W	LMP-0079
	71	24V70W	LMP-0060

LED-Lamps

TYPE	COLOR	VOLTAGE	PART NO.
ST/STPB CS	RED	24V	DE24E-R
	YELLOW	24V	DE24E-Y
	GREEN	24V	DE24E-G
	BLUE	24V	DE24E-B
	CLEAR	24V	DE24E-C
E12	RED	24V	DE24D-R
	YELLOW	24V	DE24D-Y
	GREEN	24V	DE24D-G
LGSM	RED	24V	DE24D-R
	YELLOW	24V	DE24D-Y
	GREEN	24V	DE24D-G
BA15D	RED	24V	DE24D-R
	YELLOW	24V	DE24D-Y
	GREEN	24V	DE24D-G