









Data Sheet | Item Number: 887-957
Splicing Connector Set; L-BOXX® Mini; 221 Series - 4mm² and 6mm²

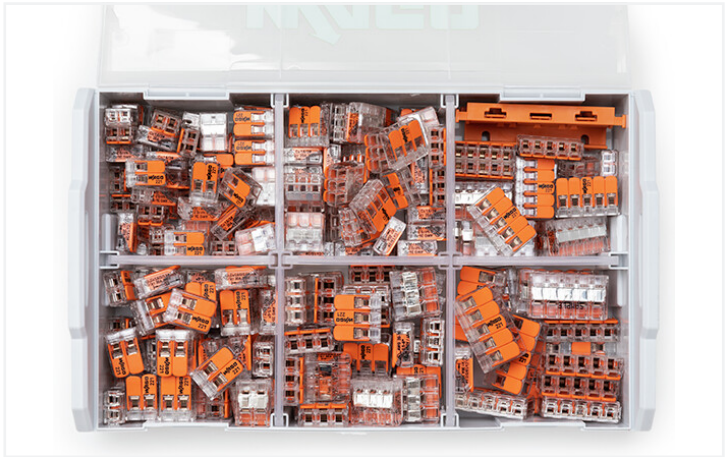

<https://www.wago.com/887-957>



This item includes:

 Item No.: 221-412 COMPACT Splicing Connector; for all conductor types; max. 4 mm²; 2-conductor; with levers; transparent housing; Surrounding air temperature: max 85°C (T85); 4,00 mm²; transparent	 Item No.: 221-413 COMPACT Splicing Connector; for all conductor types; max. 4 mm²; 3-conductor; with levers; transparent housing; Surrounding air temperature: max 85°C (T85); 4,00 mm²; transparent	 Item No.: 221-415 COMPACT Splicing Connector; for all conductor types; max. 4 mm²; 5-conductor; with levers; transparent housing; Surrounding air temperature: max 85°C (T85); 4,00 mm²; transparent	 Item No.: 221-500 Mounting carrier; 221 Series - 4 mm²; for DIN-35 rail mounting/screw mounting; orange	1
 Item No.: 221-612 COMPACT Splicing Connector; for all conductor types; max. 6 mm²; 2-conductor; with levers; transparent housing; Surrounding air temperature: max 85°C (T85); 6,00 mm²; transparent	 Item No.: 221-613 COMPACT Splicing Connector; for all conductor types; max. 6 mm²; 3-conductor; with levers; transparent housing; Surrounding air temperature: max 85°C (T85); 6,00 mm²; transparent	 Item No.: 221-615 COMPACT Splicing Connector; for all conductor types; max. 6 mm²; 5-conductor; with levers; transparent housing; Surrounding air temperature: max 85°C (T85); 6,00 mm²; transparent	15	

Physical data	
Width	260 mm / 10.236 inches
Height	63 mm / 2.48 inches
Depth	155 mm / 6.102 inches

Material data	
Note (material data)	Information on material specifications can be found here
Fire load	15.129 MJ
Weight	996.2 g



Commercial data		
eCl@ss 10.0		27-14-11-04
eCl@ss 9.0		27-14-11-04
ETIM 8.0		EC000446
ETIM 7.0		EC000446
PU (SPU)		1 pcs
Packaging type		Box
Country of origin		DE
GTIN		4055143739160
Customs tariff number		85369010000

Environmental Product Compliance		
RoHS Compliance Status		Compliant,No Exemption

Downloads

Environmental Product Compliance

Compliance Search

Environmental Product Compliance 887-957

↓