



Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUN 2018 (191) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Reflow solder capable to 260°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Customers Also Bought

TE Part #3-644463-3
03P MTA156 CONN ASSY 22AWG RED

TE Part #1423159-7
7012NI=RLY,STD,ON,2P,48VDC,60

TE Part #5-120628-8
LOCKING TRIOMATE ASY 8P(L)LDFF


TE Part #531477-5
TWIN LEAF CONTACT LP

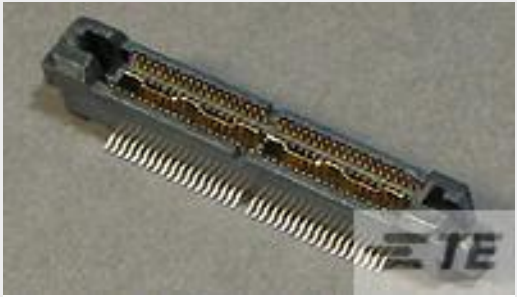

TE Part #5767111-9
MCT,PLG,076,ASY,.025 TAPE CAP




TE Part #5225973-1
PLUG, RT ANGLE, DUAL CRIMP,BNC

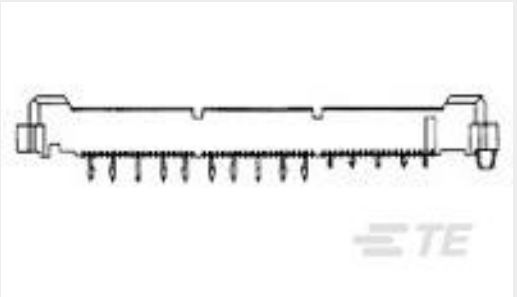

TE Part #767121-9
MCT,PLG,076,ASY,.025,TAPE PKG



TE Part #4-644695-3
13P MTA100 STR HDR RETENTIVE

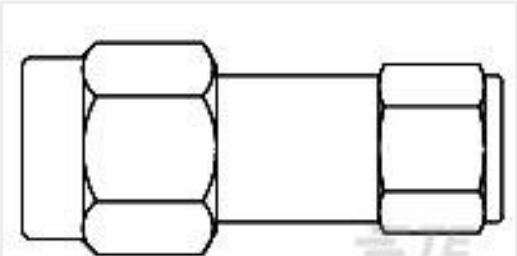

TE Part #1056706-1
ADAPTER, SMA PLUG TO SMP PLUG

Documents

Product Drawings

18P MICRO MNL ASSY,R/A,SMT LF

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_4-794625-8_J.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_4-794625-8_J.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_4-794625-8_J.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

SOFT_SHELL_PIN_AND_SOCKET_CONNECTORS_CATALOG

English

MICRO MATE-N-LOK CONNECTOR SYSTEM

English

Product Specifications

Application Specification

English



[Agency Approvals](#)
[VDE Certificate](#)
English