


# Data sheet

## CSOJ6

ENGLISH

RS Stock No. 407-1602

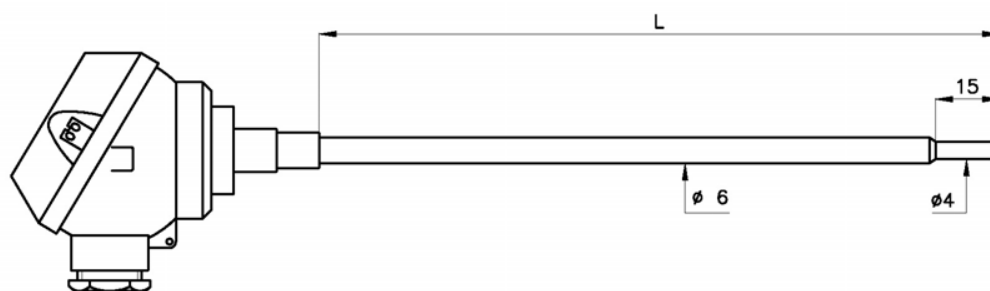

RTD SENSOR AT RESISTANCE WITH HEAD

**RANGE :**

- -50 /250°C

**USE :**

- 

**KEY POINT :**

- Fast answer time

**SPECIFICATIONS :**

- PT100Ω probe A Class – 1x3 wires
- Protector in 316L SS Ø6, sink Ø4 x 15 mm
- Connecting head in Noryl type NS12
- Borner connexion

**DIMENSIONS :**

- Length = 250 mm

**METROLOGICAL DATA :**

- Classe A :  
Norme IEC 751
- General tolerance PT100 class A :  $\pm 0.15 + 0.002 \cdot [t^{\circ}\text{C}]$

**Autre Dimensions :**

Length	100	<b>250</b>	500
Diameter	407-1595	<b>407-1602</b>	407-1618
<b>Ø6</b>			