




Part Number : [638851500](#)

Product Description : Mini-Mac Pneumatic
Applicator for Industrial Terminals 26-6 AWG

Series Number : 207127

Status : Active

Product Category : Applicators and Crimp Modules

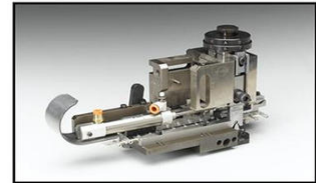

Documents & Resources

Tooling Specifications

[ATS-638851500-001.pdf](#)

[TM-640160065-001.pdf](#)

[TM-638800000-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Relevant
EU ELV	Not Relevant
Low-Halogen Status	Not Relevant
REACH SVHC	Not Relevant
EU RoHS	Not Relevant

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

Part Details

General

Status	Active
Category	Applicators and Crimp Modules
Series	207127
Description	Mini-Mac Pneumatic Applicator for Industrial Terminals 26-6 AWG
Comments	The Molex Tape Applicator requires an industry standard crimp press with a 4-way air like the Molex TM-3000: 638017200, 638017300, and the Molex TM-4000: 638017600
Function	Crimp
Geographic Area	Global
Level of Automation	Automatic, Semi-Automatic
More Detailed Tech Information	toolingsupport@molex.com
Product Name	Mini-Mac
Tool Type	Applicator
UPC	822348758654
Warranty Disclaimer	<p>CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling").</p> <p>When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer.</p> <p>Molex accepts no liability for connector performance or tooling support where tooling other than</p>

	Molex Tooling is used or where Molex Tooling is modified.
--	---

Mates With / Use With

Use with Part(s)

Description	Part Number
TM-3000 Universal Crimp Press, 120AC 50/60Hz, Used for product up to 10 AWG	<u>638017200</u>
TM-3000 Universal Crimp Press, 220AC 50/60Hz, Used for product up to 10 AWG	<u>638017300</u>
TM-4000 Universal Crimp Press, 240AC 50/60Hz, Used for product up to 4 AWG	<u>638017600</u>
Use With	Most Industry Standard Presses or Wire Process Machines

Applicable Parts

Description	Part Number
Avikrimp Quick Disconnect, Male, for 12-10 AWG (5.00-3.30mm ²) Wire, 6.35 x 0.81mm Tab, Mylar Tape	<u>190250006</u>
InsulKrimp Ring Tongue Terminal for 16-14 AWG	<u>190540091</u>
InsulKrimp Ring Tongue Terminal for 16-14 AWG	<u>190540093</u>
InsulKrimp Ring Tongue Terminal for 16-14 AWG,	<u>190540095</u>
InsulKrimp Ring Tongue Terminal for Heavy Duty 16-14 AWG Wire	<u>190540099</u>
InsulKrimp Ring Tongue Terminal for 16-14 AWG,	<u>190540127</u>
InsulKrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 6 (M3.5), Length 27.33mm, Yellow,	<u>190700120</u>

Tape	
InsulKrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 8 (M4), Length 27.40mm, Yellow, Tape	<u>190700122</u>
InsulKrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 10 (M5), Length 27.40mm, Yellow, Tape	<u>190700125</u>
InsulKrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 10 (M5), Length 31.60mm, Yellow, Tape	<u>190700131</u>
InsulKrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 1/4" (M6), Length 31.60mm, Yellow, Tape	<u>190700133</u>
InsulKrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 5/16" (M8), Length 31.60mm, Yellow, Tape	<u>190700137</u>
InsulKrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 6 (M3.5), Length 26.21mm, Yellow, Tape	<u>190700144</u>
InsulKrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 8 (M4), Length 26.21mm, Yellow, Tape	<u>190700146</u>
InsulKrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 1/4" (M6), Length 34.30mm, Yellow, Tape	<u>190700151</u>
InsulKrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 3/8" (M9), Length 34.30mm, Yellow, Tape	<u>190700154</u>
InsulKrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 5/16" (M8), Length 34.30mm, Yellow, Tape	<u>190700156</u>
Avikrimp Ring Tongue Terminal for	<u>190730162</u>

12-10 AWG Wire, Stud Size 6 (M3.5), Length 27.71mm, Yellow, Mylar Tape Carrier	
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 6 (M3.5), Expanded Flare, Length 27.71mm, Yellow, Mylar Tape Carrier	<u>190730164</u>
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 8 (M4), Length 27.71mm, Yellow, Mylar Tape Carrier	<u>190730167</u>
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 8 (M4), Expanded Flare, Length 27.71mm, Yellow, Mylar Tape Carrier	<u>190730169</u>
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 10 (M5), Length 27.71mm, Yellow, Mylar Tape Carrier	<u>190730172</u>
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 10 (M5), Expanded Flare, Length 27.71mm, Yellow, Mylar Tape Carrier	<u>190730174</u>
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 10 (M5), Length 31.95mm, Yellow, Mylar Tape Carrier	<u>190730180</u>
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 10 (M5), Expanded Flare, Length 31.95mm, Yellow, Mylar Tape Carrier	<u>190730184</u>
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 1/4" (M6), Length 31.95mm, Yellow, Mylar Tape Carrier	<u>190730190</u>
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 1/4" (M6), Expanded Flare, Length 31.95mm, Yellow, Mylar Tape Carrier	<u>190730194</u>
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 5/16" (M8), Length 31.95mm,	<u>190730201</u>

Yellow, Mylar Tape Carrier	
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 5/16" (M8), Expanded Flare, Length 31.95mm, Yellow, Mylar Tape Carrier	<u>190730205</u>
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 6 (M3.5), Length 26.59mm, Yellow, Mylar Tape Carrier	<u>190730218</u>
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 8 (M4), Length 26.59mm, Yellow, Mylar Tape Carrier	<u>190730224</u>
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 8 (M4), Expanded Flare, Length 26.59mm, Yellow, Mylar Tape Carrier	<u>190730226</u>
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 10 (M5), Length 34.59mm, Yellow, Mylar Tape Carrier	<u>190730228</u>
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 1/4" (M6), Length 34.59mm, Yellow, Mylar Tape Carrier	<u>190730232</u>
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 1/4" (M6), Expanded Flare, Length 34.59mm, Yellow, Mylar Tape Carrier	<u>190730234</u>
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 3/8" (M9), Length 34.59mm, Yellow, Mylar Tape Carrier	<u>190730237</u>
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 3/8" (M9), Expanded Flare, Length 34.59mm, Yellow, Mylar Tape Carrier	<u>190730239</u>
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 5/16" (M8), Length 34.59mm,	<u>190730243</u>

Yellow, Mylar Tape Carrier	
Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 5/16" (M8), Expanded Flare, Length 34.59mm, Yellow, Mylar Tape Carrier	<u>190730245</u>
InsulKrimp Ring Tongue Terminal for 12-10 AWG Heavy Duty Wire, Stud Size 6, 8, 10	<u>190800006</u>
InsulKrimp Snap Spade Terminal for 12-10 AWG Wire, Yellow	<u>190990045</u>
InsulKrimp Snap Spade Terminal for 12-10 AWG Wire, Yellow	<u>190990049</u>
InsulKrimp Snap Spade for 12-10 AWG Wire, Stud Size 10 (M5), Mylar Tape Carrier, Yellow	<u>190990051</u>
Avikrimp Snap Spade Terminal for 12-10 AWG Wire	<u>191150043</u>
Avikrimp Snap Spade Terminal for 12-10 AWG Wire, Tape and Reel, Stud Size 8 (M4)	<u>191150047</u>
Avikrimp Snap Spade Terminal for 12-10 AWG Wire, Tape and Reel, Stud Size 10 (M5)	<u>191150049</u>
InsulKrimp Flanged Spade Tongue Terminal for 12-10 AWG Wire, Stud Size 8 (M4), Width 8.13mm, Mylar Tape Carrier	<u>191210048</u>
InsulKrimp Flanged Spade Tongue Terminal for 12-10 AWG Wire, Stud Size 8 (M4), Width 9.53mm, Mylar Tape Carrier	<u>191210054</u>
InsulKrimp Flanged Spade Tongue Terminal for 12-10 AWG Wire, Stud Size 10 (M5), Width 9.53mm, Mylar Tape Carrier	<u>191210057</u>
Avikrimp Flanged Spade Tongue Terminal for 12-10 AWG Wire, Stud Size 8 (M4), Mylar Tape Carrier	<u>191270087</u>
Avikrimp Flanged Spade Tongue Terminal for 12-10 AWG Wire, Stud Size 10 (M5), Mylar Tape Carrier	<u>191270090</u>

InsulKrimp Block Spade Tongue Terminal for 12-10 AWG Wire, Stud Size 8 (M4), Length 27.31mm	<u>191310003</u>
InsulKrimp Spade Tongue Terminal for 12-10 AWG Wire, Tape and Reel	<u>191440041</u>
InsulKrimp Spade Tongue Terminal for 12-10 AWG Wire, Tape and Reel	<u>191440043</u>
InsulKrimp Butt Splice for 12-10 AWG Wire, Tape and Reel	<u>191540030</u>
Avikrimp Hook Tongue Terminal for 12-10 AWG Wire, Stud Size 10 (M5), Mylar Tape Carrier	<u>191830020</u>
Avikrimp Block Spade Terminal for 12-10 AWG Wire	<u>191980040</u>
Avikrimp Spade Tongue Terminal for 12-10 AWG Wire, Stud Size 8 (M4), Mylar Tape Carrier	<u>191980048</u>
Avikrimp Spade Tongue Terminal for 12-10 AWG Wire, Stud Size 10 (M5), Mylar Tape Carrier	<u>191980051</u>
Avikrimp Wire Pin Terminal for 12-10 AWG Wire, Mylar Tape Carrier	<u>192130008</u>
Avikrimp Metric Ring Terminal for Stud Size 8 (M4), Yellow Insulated Barrel, Tape Mounted	<u>193240042</u>
Avikrimp Metric Ring Terminal for Stud Size 10 (M5), Yellow Insulated Barrel, Tape Mounted	<u>193240018</u>
Avikrimp Metric Ring Terminal for Stud Size 1/4" (M6), Yellow Insulated Barrel, Tape Mounted	<u>193240044</u>
Avikrimp Metric Ring Terminal for Stud Size 5/16" (M8), Yellow Insulated Barrel, Tape Mounted	<u>193240046</u>
Avikrimp Metric Ring Terminal for Stud Size 3/8" (M10), Yellow Insulated Barrel, Tape Mounted	<u>193240048</u>