



## CONCEALED SPRINGLOADED PIN HINGES


### A

**12-1-3854**

Stainless steel spring. Hinges in raw steel and zinc plated steel with a zinc plated pin. Circlip in 1.4122 stainless steel.

<b>Material</b>	steel
<b>Finish</b>	zinc plated

<b>Note</b>	type 2
<b>Weight (g)</b>	46 g
<b>Opening angle</b>	270 °
<b>Functions</b>	

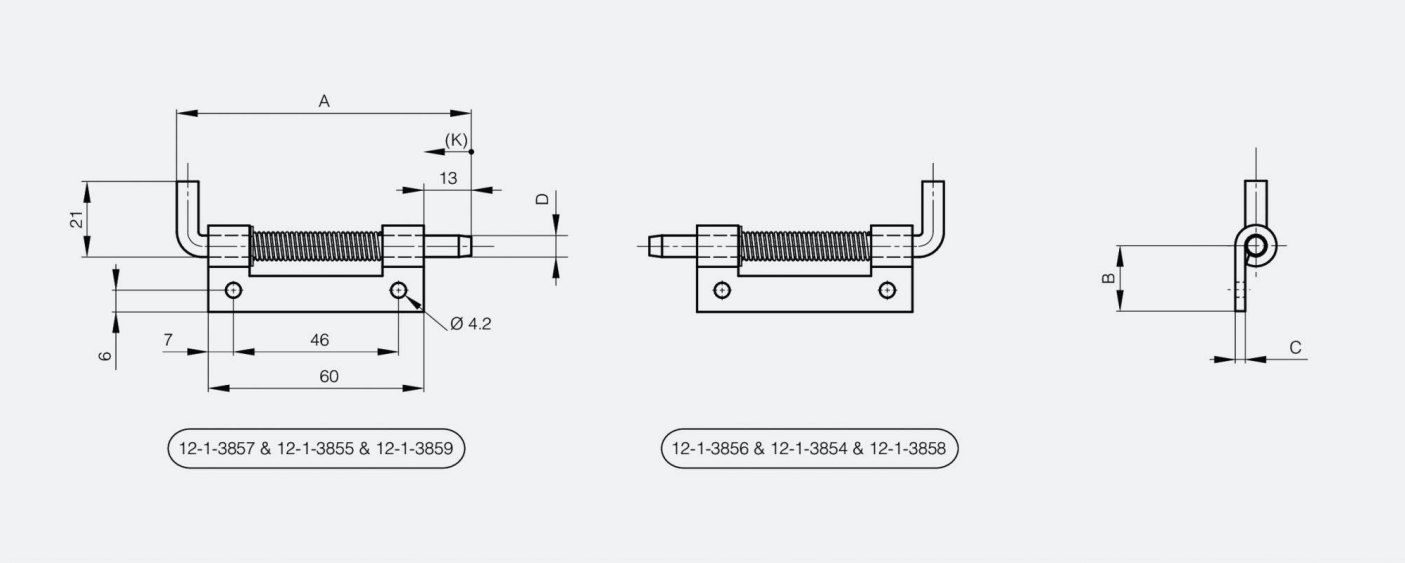

<b>A (length)</b>	82 mm
<b>B (width)</b>	18.2 mm
<b>C</b>	2.8 mm
<b>D (pin diameter)</b>	6
<b>K</b>	12 mm