


# push-in T-connector NPQM-T-Q4-S4-P10

Part number: 558791

FESTO

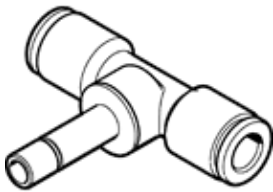

## Data sheet

Feature	Value
Size	Standard
Nominal size	3 mm
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-:]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-20 ... 70 °C
Product weight	18.5 g
Pneumatic connection, port 1	Push-in sleeve QS-4
Pneumatic connection, port 2	For tubing outside diameter 4 mm
Materials note	Conforms to RoHS
Material housing	Nickel-plated brass
Material of tubing seal	NBR