



UN38.3 试验概要

UN38.3 Test Summary



811900400758031

#QS #XUHUA.LIANG #LEDVANCE PLP(V)

#LAB-#LVD AC01667 - UN38.3 Summary Test report #

#2020-08-07 #

#RL-Released

9C1 5000015-EN-00

单位信息 Company information			
委托单位 Consignor	杭州庄诚进出口有限公司 HANGZHOU JUNCTION IMP.&EXP.CO.,LTD. 杭州市滨江区西兴街道滨文路 95 号 7 幢 4 楼 4F,NO.7 Building,NO.95 Binwen Road,Xixing Street,Binjiang District,Hangzhou, Zhejiang,China,310051 15088614493 fanghx@jncighting.com www.jncighting.com		
生产单位 Manufacturer	深圳市博富能电池有限公司 ShenZhen BOFUNENG BATTERY CO.,LTD 深圳市龙岗区龙城街道五联社区朱古石春洋工业园 A 栋厂房 A Building,Chun yang Industrial park,Zhugushi Road,Wulian community,Long Cheng Street,Longgang District 0755-84642975 aijuan_1425@126.com www.bfnbattery.com		
测试单位 Test lab	上海化工研究院检测中心 Shanghai Research Institute of Chemical Industry Testing Center 中国.上海.普陀区云岭东路 345 号, 200062 No.345 East Yunling Road, Putuo, Shanghai, China 200062 86-21-31765555 battery@ghs.cn www.ghs.cn		
电池信息 Battery information			
名称 Name	锂电池	品牌 Brand	/
型号 Type	CNB 18650	原始测试型号 Original tested type	/
标称电压(V) Nominal voltage	3.7	容量/能量 Capacity/energy	1800mAh
描述 Description	可充电锂离子单电芯电池 Rechargeable Li-ion single cell battery	锂含量(g) Li content	/
质量(kg) Mass	0.0465	外观 Appearance	蓝色圆柱型塑料薄膜外壳 Blue cylinder plastics film shell
测试信息 Test information			
原报告编号 Original test report No.	1117030241	测试报告日期 Date of test report	2017-05-05
测试标准 Test standard	联合国《关于危险货物运输的建议书 试验和标准手册》第 38.3 章 UNITED NATIONS "Recommendations on the TRANSPORT OF DANGEROUS GOODS" Manual of Tests and Criteria 38.3 ST/SG/AC.10/11/Rev.5/Amend.1&Amend.2		
T.1 高度模拟 Altitude simulation	合格 Passed	T.2 温度测试 Thermal test	合格 Passed
T.3 振动测试 Vibration	合格 Passed	T.4 冲击测试 Shock	合格 Passed
T.5 外部短路 External short circuit	合格 Passed	T.6 撞击 Impact	合格 Passed
T.7 过度充电 Overcharge	合格 Passed	T.8 强制放电 Forced discharge	合格 Passed
38.3.3 (f)	/	38.3.3 (g)	/



声 明

Statement

1. 试验概要无本实验室公章（或检验检测专用章）无效。

The test summary is invalid if it is not affixed the official seal of the laboratory to it.

2. 复制试验概要未重新加盖本实验室公章（或检验检测专用章）无效。

Copies of the test summary without the official seal of the laboratory are invalid.

3. 试验概要无签字及签字者姓名和职务无效。

The test summary is invalid without the signature, name and title of the signatory.

4. 试验概要涂改无效。

The test summary is invalid if it is blotted out.

5. 未经本实验室书面批准，不得部分复制试验概要。

It is forbidden to copy the test summary partially without the written approval of the laboratory.

6. 试验概要中描述的检测结果，仅对所测样品有效。

The conclusion of the test summary is only valid for the tested sample.

7. 试验概要以中文为准，英文文本（如有）仅为译文，两者发生冲突时，应以中文文本为准。

The test summary has been drafted in Chinese and translated into English (if exist) for convenience only. In the event of discrepancy, the Chinese version shall prevail.

地址：上海市云岭东路 345 号 Address: No. 345 East Yunling Road, Shanghai



邮政编码(PostCode): 200062

电话(Tel): (021) 31765555 传真(Fax): (021) 31015117

网址(website): www.ghs.cn

电子信箱(E-mail): battery@ghs.cn

样品图片 Sample Picture

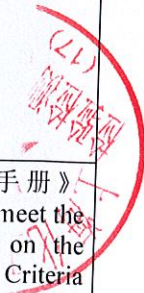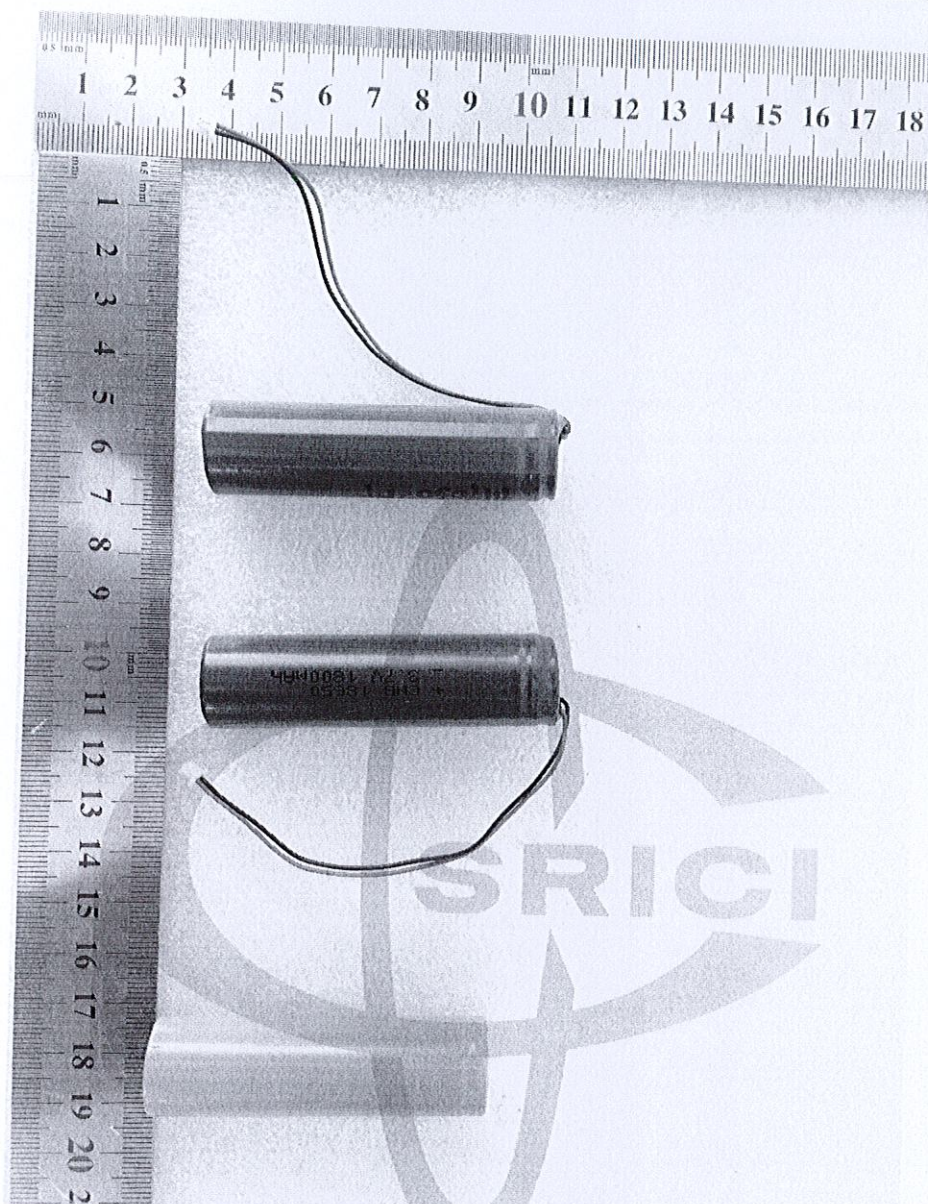

结论 Conclusion	测试样品符合联合国《关于危险货物运输的建议书试验和标准手册》ST/SG/AC.10/11/Rev.5/Amend.1&Amend.2 38.3 标准要求。The tested samples meet the requirements of test items of the UNITED NATIONS "Recommendations on the TRANSPORT OF DANGEROUS GOODS" Manual of Tests and Criteria ST/SG/AC.10/11/Rev.5/Amend.1&Amend.2 38.3		
备注 Remark	/		
签名 Signature 职务 Title	王真 副总工程师 Vice chief engineer	签发日期 Issued date	2019-12-21



-验证码:683366-

报告结束