
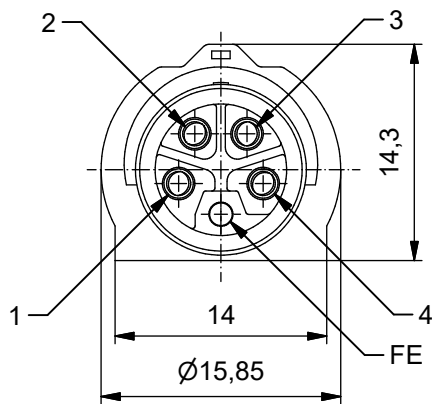
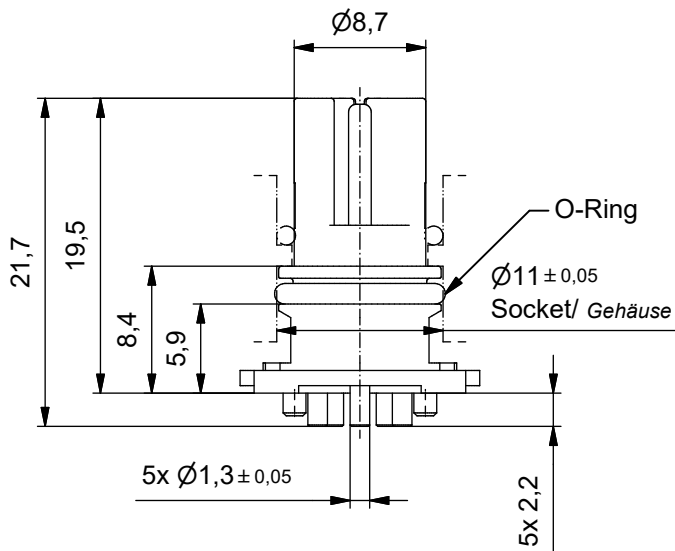


Tape & Reel -
parts with adhesive
pad Ø11mm
TR-Artikel mit
Klebe pad Ø11mm

Top view
Layout PCB/
Leiterplatte

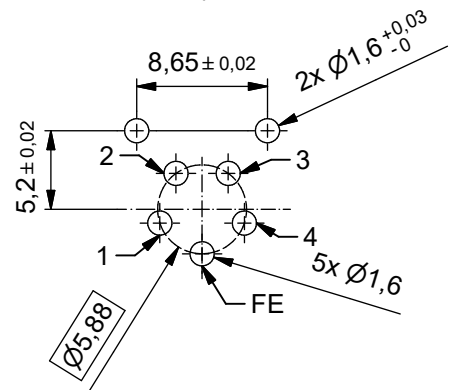

Technical specification/

Technische Daten:

Rated Voltage/ Bemessungsspannung: IEC 61076-2-111	63 V AC / 63 V DC
Current rating/ Strombelastbarkeit: IEC 61076-2-111	16 A / 40 °C
Insulation resistance/ Isolationswiderstand: IEC 60512	>=100 MΩ
Pollution degree/ Verschmutzungsgrad: IEC 60664-1	3/2
Degree of protection/ Schutzart: IEC 60529	IP 67, in mated condition/ im verschraubten Zustand
Temperature range/ Umgebungstemperatur:	-40 °C ... +105 °C
Mating cycles/ Steckzyklen: IEC 60512-9a	>=100


Materials/

Werkstoffe:

Contact/ Kontakt:	CuZn, Ni b / Au 0,2 gal.
Contact carrier/ Kontaktträger:	PA, UL 94 V-0
Sealing/ Dichtung:	FKM

Suitable for reflow soldering
max. 60s / 250°C
geeignet für Reflow Lötprozess
max. 60s / 250°C

Part no packing unit Tape & Reel/ Art.-Nr. Verpackungseinheit Rolle:	Part no. packing unit in bulk/ Art.-Nr. Verpackungseinheit lose:	Description/ Beschreibung:	Pos/ Pol:
43-03908TR	43-03908	SAL- 12L - IKO4FE / THR	5

 

dim. in mm

Female socket M12x1 L-coded THR 4pos. + FE
Flansch Kupplung M12x1 L-Codiert THR 4pol + FE

general tolerance/ Allgemeintoleranz:	0 ± 0,50 mm 0,0 ± 0,25 mm 0,00 ± 0,10 mm * ± 1,5°
--	--

	Date/Datum	Name
drawn/ gez.	30.10.2020	Bludau
appd./ gepr.	02.11.2020	Fischer

Index: b Ä21-0446 09.12.21 ABL

scale/Maßstab:

CONEC®

dwg no /
Z.-nr.:

43K1A4669

DIN-
A4

RoHS & REACH compliant/konform

see table

1 / 1