 

 
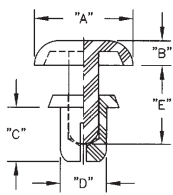


FORM 1




FORM 2

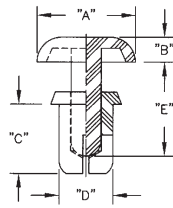

FORM 3

KOPFFORM BEI SR-5000 SERIE

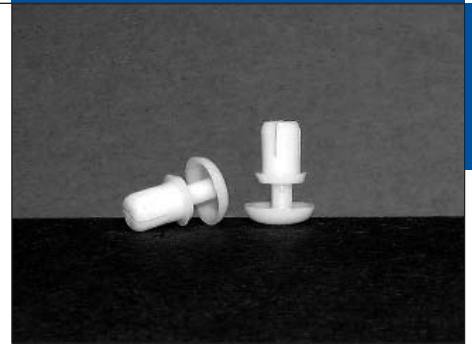

SR/SRV0

KUNSTSTOFF-SPREIZNIETE
PATENT NR. 232519

Artikel Nr.		RMS	Artikel Nr.		"C" mm	Belastung kg	"F" Befestigungsber.	"A" ±0.2mm	"B" ±0.2mm	"C" ±0.3mm	"D" ±0.2mm	"E" ±0.3mm	Form												
Weiss	Schwarz		Schwarz																						
SR-2024W	SR-2024B	28			2.1-2.2	3	0.6 - 1.2	4.2	1.2	2.4	2.0	2.8	1												
SR-2032W	SR-2032B																								
SR-2040W	SR-2040B																								
SR-2048W	SR-2048B																								
SR-2056W	SR-2056B															SRV0-2066									
SR-2064W	SR-2064B																								
SR-2632W	SR-2632B						SRV0-2642	2.6-2.7	5	1.0 - 2.0	5.0	1.4		3.2	2.6	4.5									
SR-2642W	SR-2642B																								
SR-2648W	SR-2648B																								
SR-2655W	SR-2655B																								
SR-2664W	SR-2664B																SRV0-2644								
SR-2672W	SR-2672B																SRV0-2672								
SR-3035W	SR-3035B						SRV0-3035	3.1-3.2	8	1.0 - 2.0	6.4	1.6		3.5	3.0	5.1									
SR-3045W	SR-3045B						SRV0-3045																		
SR-3055W	SR-3055B						SRV0-3055																		
SR-3065W	SR-3065B						SRV0-3065																		
SR-3075W	SR-3075B						SRV0-3075																		
SR-3080W	SR-3080B						SRV0-3080																		
SR-3090W	SR-3090B						SRV0-3090																		
SR-3100W	SR-3100B						SRV0-3100																		
SR-3230W	SR-3230B						SRV0-3230																		
SR-3535W	SR-3535B						SRV0-3535	3.6-3.7	12	1.2 - 2.1	8.0	1.8		3.5	3.5	5.1									
SR-3545W	SR-3545B						SRV0-3545																		
SR-3550W	SR-3550B						SRV0-3550																		
SR-3555W	SR-3555B						SRV0-3555																		
SR-3560W	SR-3560B						SRV0-3560																		
SR-3570W	SR-3570B						SRV0-3570																		
SR-3580W	SR-3580B						SRV0-3580																		
SR-4050W	SR-4050B			SRV0-4050	4.1-4.2	20	2.5 - 3.5	8.0	1.8	5.0	4.0	7.1													
SR-4060W	SR-4060B			SRV0-4060																					
SR-4070W	SR-4070B			SRV0-4070																					
SR-4080W	SR-4080B			SRV0-4080																					
SR-4090W	SR-4090B			SRV0-4090																					
SR-4100W	SR-4100B			SRV0-4100																					
SR-4120W	SR-4120B			SRV0-4120																					
SR-5045W	SR-5045B			SRV0-5045	5.1-5.2	25	1.5 - 2.5	9.0	2.2	4.5	5.0	6.5													
SR-5055W	SR-5055B			SRV0-5055																					
SR-5065W	SR-5065B			SRV0-5065																					
SR-5075W	SR-5075B			SRV0-5075																					
SR-5085W	SR-5085B			SRV0-5085																					
SR-5095W	SR-5095B			SRV0-5095																					
SR-5105W	SR-5105B			SRV0-5105																					
SR-6060W	SR-6060B				6.1-6.2	30	2.5 - 4.0	12.0	2.5	6.0	6.0	9.0													
SR-6080W	SR-6080B																								
													2												

Bestellinfo:

SR 2024 W od. B
Artikel Größe Farbe

Material: Nylon 6, UL 94 V-2, RMS-28
oder
Nylon 6, UL 94 V-0, RMS-87
Farbe: bitte der Tabelle entnehmen
VPE: 1.000 Stk.

Bestellinfo:

SR V0 3035
Artikel Material Größe