


Polyurethane-tyred wheel Ø 100 roller bearing, 230kg

Heavy duty wheel

PRODUCT

Article number

23-412-100R12

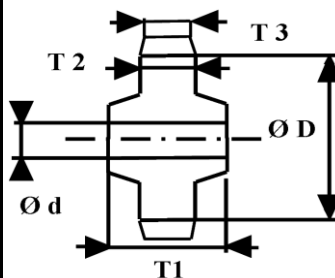

Product Details

Wheel Rim : machined high-resistance engineered cast iron.

Tyre : cast bonded polyurethane.

Hub : symmetrical, with roller bearing.

Specifications

Wheel Diameter - Ø D ± 1%	100 mm
Hub Type	Roller bearing
Hub Length T1	45 mm ±1
Width of Tread T2	29 mm ±1
Width of Tread-on floor T3	29 mm
Axle Hole Ø d	Ø 12 mm
Hardness of tread A ±3	A 93 Shore
Load capacity	230 Kg
Temperature	-25 / +70 °C

TECHNICAL DATA

Applications :

Materials handling of very heavy loads.

Low starting effort.

High degree of resistance to abrasion, wear, hydrocarbons and metal shavings.