


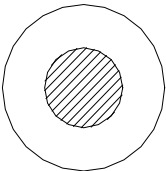

Datasheet

Product Name:	UL1429 26AWG
Product Discription:	UL1429 26AWG
Specification No.:	
Customer's Name:	

Description		Construction			
Rated Voltage:	150V	Conductor	Stranded Tinned Copper		
Rated Temperature:	80°C	Size(AWG)	26		
Reference Standard:	UL758,UL1581	Construction(±0.008mm)	7/0.16		
Cross Section		Stranded Dia.(mm)Ref.	0.48		
		Insulation Material	XLPVC		
		Insulation Color	ANY COLOR		
		Ave Thickness(mm)	0.26		
		Insulation Dia.(±0.06mm)	1.00		

Marking	Remark:
E148000  AWM STYLE 1429 26AWG 80°C 150V VW-1 --- C  AWM I A 80°C 150V FT1 -F- -LF- PC10 LTK	8775291 Red 8775294 Blue 8775314 Grey 8775317 Violet 8775288 Black 8775298 White 8775301 Yellow 8775282 Brown 8775308 Green 8775305 Orange

Applications					Characteristics		Customer Approve
For Internal Wiring of Appliances or Electronic Equipment					Test Item	Standard Value	Seal & Stamp Signature: Date:
					Test Material	XLPVC(ROHS)	
					Insulation DC resistance(MΩ*km)	10	
					Vol. Tesr(AC.V.60S) (V)	2000	
					Flammability Test	VW-1	
					Max.DC Resistance(20°C Ω/km)	150(MAX)	
Revisions							
Version	Description	Drawn by	Approved by	Date			
0	New document issue	Lisa	Jason	18/05/2015			