


## TECHNICAL SPECIFICATION • BETADUCT NORYL - CLOSED SLOT MINI PACKS

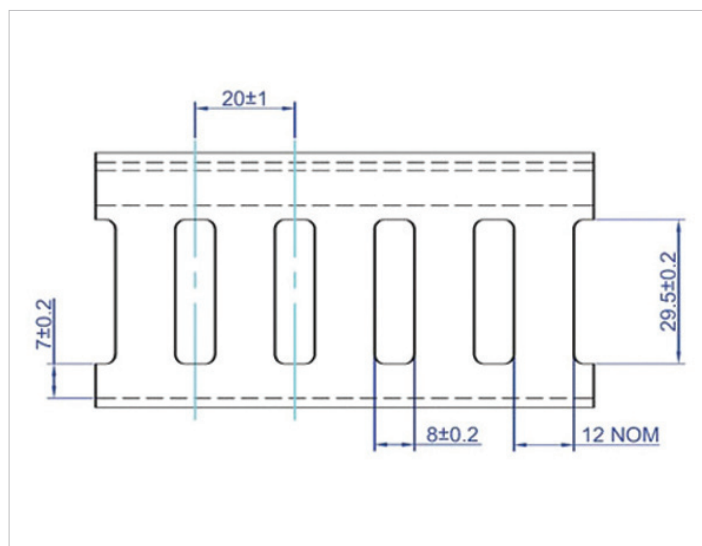

### DESCRIPTION

The Noryl Betaduct range is free from toxic halogens, has excellent low smoke characteristics and high operating temperatures. Noryl Betaduct is recommended for areas when human life or electronic components are at risk. Supplied in handy mini packs containing 4 x 1 metre packs. Recommended fixing method; Betaduct rivets and washers

### APPLICATION

For use when bundles, cables and wires need supporting in control panels, distribution boards and switchgear. Designed and specified for installations in hazardous applications such as rail, underground, marine, mass transit and military applications. Widely used in petrochemical plants and off shore oil and gas installations and accommodation modules.

### SPECIFICATION

<b>Material:</b>	Self-Extinguishing, Noryl Extra, Halogen-Free
<b>Colour Options:</b>	Black
<b>Service Temperature Range:</b>	-30°C to +120°C
<b>Flammability:</b>	UL94 V-0 Rated Material BS 476 Part 7 Class I (Y)
<b>Standards:</b>	UL and Lloyds Register Base slots to DIN 43659.

### PART NUMBERS & SIZES

PART NO.	NOMINAL SIZE INNER WxH (MM)	PACK QTY (METRES)
<b>05870000</b>	25 x 50	4 x 1m
<b>05880000</b>	50 x 50	4 x 1m
<b>05910000</b>	75 x 75	4 x 1m