



9490

Remote Area Lighting Systems from Peli are the complete lighting solution for first responders, industrial and aerospace applications.

- Built Peli tough
- Full time battery level indication with low level flashing indicator
- Deployable mast with 340 degree rotation
- Multiple deployment positions
- Convenient shoulder strap
- Quick release / Hot swappable battery design with 12 volt power supply
- Up to 6,000 lumens (calculated)
- Up to 24 hrs of run time
- Intelligent Control (allows for various light output levels)



DIMENSIONS

Head (LxWxD)	8.25 x 5.75" x 2.25 (21 x 14.6 x 5.7 cm)
Closed (LxWxD)	20.00 x 6.50" x 11.25 (50.8 x 16.5 x 28.6 cm)
Light Head Height (max)	72.00" (182.9 cm)

MATERIALS

Body	Polypropylene
Head	Aluminum
Mast	Aluminum
Lens	Polycarbonate (PC)

COLOURS

 Black	 Yellow
---	--

LIGHT SPECS

Lumens (High)	6000
Lamp Heads	1
Lamp Type	LED
Number of LEDs	10
Beam Spread	125°
IP Rating	54

POWER

Run Time (High)	3.50 hrs
Run Time (Med)	12.00 hrs
Run Time (Low)	24.00 hrs
Battery Type	Sealed Lead Acid (SLA)
Rechargeable	yes
Battery Lifespan	500 cycles

Charge Time	8 hrs
Battery Level Indicator	Full-time battery level display and low battery warning (visible flashing)
Sockets (Primary)	1
Volts	12.0v


WEIGHT

Weight	32.00 lbs (14.5 kg)
---------------	---------------------

SWITCH

Switch Type	Silicone Rubber Keypad
Light Modes	High / Medium / Low / Flashing

ACCESSORIES

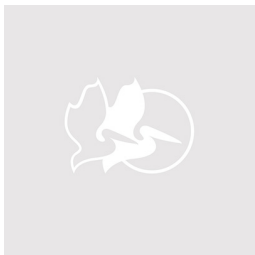

9483
Power Supply



9487
Padded Shoulder Strap



9489
Powerpack



9447
DC Vehicle Charger Cord

Peli
c/ Provença, 388, Planta 7 • Barcelona, Spain 08025 • Phone: +34 934 674 999
info@peli.com • www.peli.com

Document created on 05-09-25