


suction cup VASB-75-1/4-SI-B

Part number: 1378427

FESTO

Sealing ring is not included in the scope of delivery.

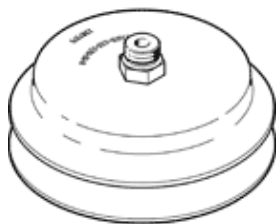

Data sheet

Feature	Value
Suction cup height compensator	15.5 mm
Nominal size	4 mm
suction cup diameter	75 mm
suction cup volume	65.5 cm ³
Position of connection	on top
Assembly position	Any
Suction cup shape	Round, bellows 1.5 conv
Operating pressure	-0.95 ... 0 bar
Nominal operating pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Food-safe	See Supplementary material information
Ambient temperature	-40 ... 200 °C
Retention force at nominal operating pressure	228 N
Product weight	78 g
Mounting type	Via vacuum port
Vacuum connection	G1/4
Colour	transparent
Shore hardness	60 +/- 5
Material of threaded plug	Wrought Aluminium alloy
Materials note	Contains PWIS substances Conforms to RoHS
Material suction cup	VMQ (silicon)