

1/2" SOCKETS WRENCHES 1000V



EGA Master insulated tools comply with IEC 60900 international standard, each one of the pieces being tested at 10,000V (10 times the voltage we certify). They are also tested rigorously according to what the norms establishes: adherence test, impact test, flame propagation test and dielectric penetration test.



MAIN APPLICATION FIELDS

Electrical installation	High Voltage networks	Electric maintenance
Power Plants	Low Voltage networks	Fire-fighters
Electric Stations and substations	Telecommunications	Lighting installation and repair


CAUTION

- 1 Don't ever use tools under voltage if they present pores, fissures, encrusted elements or if the white insulation layer is visible.
- 2 Insulating floors and safety shoes are recommended to work under voltage.
- 3 Avoid contact with water while working under voltage.
- 4 Do not ever touch directly any item that may be under voltage. Use a voltage tester to check first.

STANDARD

MM

6 PT.

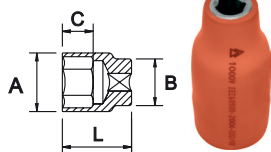


COD.	AF mm	L (mm)	A (mm)	B (mm)	C (mm)	Pt	g	
74960	8		14		5,0	50		
74961	9		15					
74962	10		16		6,0			
74963	11		17		7,0			
74964	12		18	21	8,0	55		
74965	13		19					
74966	14		21					
74967	15		22		10	60		
74968	16	40	24	22		70		
74969	17		26	23				
74970	18		28	26	12	90	10	
74971	19		30		14	95		
74972	20		32	31		110		
74973	21		34		16	140		
74974	22	44	36		18	150		
74975	23		38	34	20	160		
74976	24		40		22	170		
74977	25		42	38	22	180		
74978	26	45	44			200		
74979	27		46			210		

1000V I IEC 60900

INCH


6 PT.

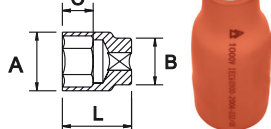

COD.	AF inch	L (mm)	A (mm)	B (mm)	C (mm)	Pt	g	
75000	5/16		15			45		
75001	3/8		16			50		
75002	7/16		17			55		
75003	1/2		18	22	14			
75004	9/16		21					
75005	19/32		22			60		
75006	5/8		24	23	16	70		
75007	21/32	38	26	26		80		
75008	11/16		28	28	20	90	10	
75009	3/4		30			110		
75010	25/32		32			120		
75011	13/16		34			130		
75012	7/8		36	30		140		
75013	15/16		38			145		
75014	31/32	42	40	31	28	160		
75015	1		42			170		
75016	1.1/16	45	44			180		
75017	1.1/8		46			200		

1000V I IEC 60900


12 PT.

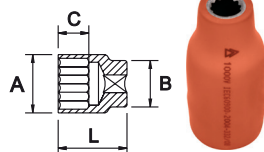

COD.	AF mm	L (mm)	A (mm)	B (mm)	C (mm)	Pt	g	
73400	8		14		5,0	50		
73401	9		15					
73402	10		16		6,0			
73403	11		17		7,0			
73404	12		18	21	8,0	55		
73405	13		19					
73406	14		21					
73407	15		22		10	60		
73408	16	40	24	22		70		
73409	17		26	23				
73410	18		28	26	12	90	10	
73411	19		30		14	95		
73412	20		32	31		110		
73413	21		34		16	140		
73414	22	44	36		18	150		
74991	23		38	34	20	160		
73416	24		40		22	170		
74992	25		42	38	22	180		
74993	26	45	44			200		
73417	27		46			210		

1000V I IEC 60900

12 PT.

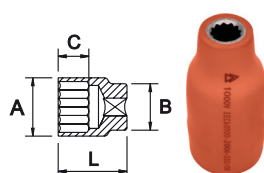

COD.	AF inch	L (mm)	A (mm)	B (mm)	C (mm)	Pt	g	
73491	5/16		15			45		
73492	3/8		16			50		
73493	7/16		17			55		
73494	1/2		18	22	14			
73495	9/16		21					
73496	19/32		22			60		
73497	5/8		24	23	16	70		
73498	21/32	38	26	26		80		
73499	11/16		28	28	20	90	10	
73500	3/4		30			110		
75025	25/32		32			120		
73501	13/16		34			130		
73502	7/8		36	30		140		
73503	15/16		38			145		
75028	31/32	42	40	31	28	160		
75029	1		42			170		
75030	1.1/16	45	44			180		
75031	1.1/8		46			200		


1000V I IEC 60900

1/2"

LONG SocketsT

MM

6 PT.

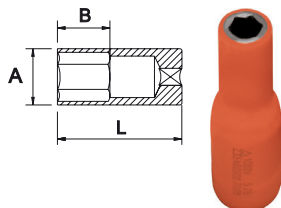


COD.	AF mm	L (mm)	A (mm)	B (mm)	Pt	g	
73430	10		17	9,0			
73431	11		18	11			
73432	12		19	12			
73433	13		21		140		
73434	14		22				
73435	15		23	15			
73436	16		24		150		
73437	17		26		180		
73438	18		28	18	200		10
73439	19	75	30		250		
73440	21		32	21	280		
73441	22		34	24	370		
73442	23		36		430		
73443	24		38	27	450		
75205	26		40	30	500		
75206	27		42				
75207	28						
75208	29						
75209	30						
75210	32						

1000V IEC 60900

INCH


6 PT.

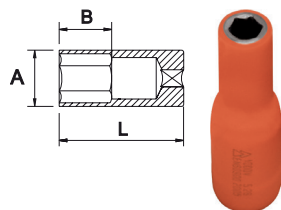

COD.	AF inch	L (mm)	A (mm)	B (mm)	Pt	g	
73378	3/8		17	6,0			
73379	7/16		19	7,0			
73380	1/2		20	8,0	140		
73381	9/16		22	10			
73382	5/8	75	24	15	150		10
73383	11/16		26		170		
73384	3/4		28	18	200		
73385	13/16		30	21	250		
73386	7/8		32	24	290		
73387	15/16						

1000V IEC 60900


12 PT.

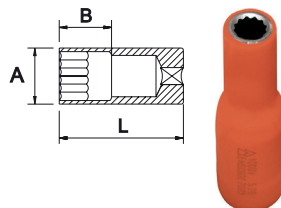

COD.	AF mm	L (mm)	A (mm)	B (mm)	Pt	g	
75180	10		17	9,0			
75181	11		18	11			
75182	12		19	12			
75183	13		21		140		
75184	14		22				
75185	15		23	15			
75186	16		24		150		
75187	17		26		180		
75188	18		28	18	200		10
75189	19	75	30		250		
75191	21		32	21	280		
75192	22		34	24	370		
75193	23		36		430		
75194	24		38	27	450		
75195	26		40	30	520		
75196	27		42				
75197	28						
75198	29						
75199	30						
75200	32						

1000V IEC 60900

12 PT.

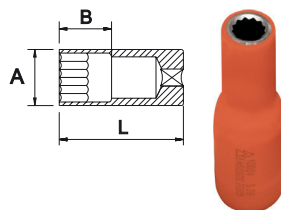

COD.	AF inch	L (mm)	A (mm)	B (mm)	Pt	g	
75215	3/8		17	6,0			
75216	7/16		19	7,0			
75217	1/2		20	8,0	140		
75218	9/16		22	10			
75219	5/8	75	24	15	150		10
75220	11/16		26		170		
75221	3/4		28	18	200		
75222	13/16		30	21	250		
75223	7/8		32	24	290		
75224	15/16		36		330		
75225	1		38	24	380		
75226	1.1/16				410		
75227	1.1/8						

1000V IEC 60900

1/2"

REVERSIBLE RATCHET HANDLE

COD.	AF inch	L (mm)	g		
73683	1/2	235	645	6	•

△ 1000V I IEC 60900



EXTENSION

COD.	AF inch	L (mm)	g		
73445	1/2	125	260	5	•
73446		250	360		

△ 1000V I IEC 60900



T HANDLE

COD.	AF inch	L (mm)	g		
73448	1/2	200	600	6	•

△ 1000V I IEC 60900



SocketsT BITS

HEXAGONAL

COD.	AF mm	g	
73455	4	75	
73456	5		
73457	6		
73458	7	80	
73459	8	85	
73460	9	90	
73461	10	95	
73462	11		
73463	12		
73464	13	135	
73465	14		
73468	17	160	

△ 1000V I IEC 60900



ADAPTER

COD.	AF inch	AF inch	g		
73286	1/2-1/4		80	5	•
73449	1/2-3/8				

△ 1000V I IEC 60900




1/2"

SocketsT WRENCHES SETS

10 PCS.

STANDARD

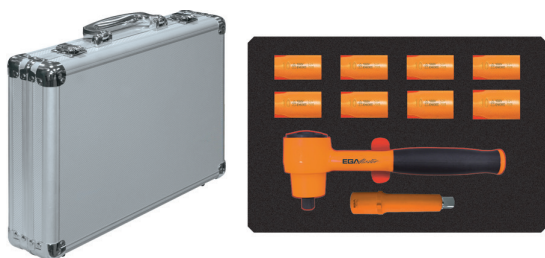


COD.	PCS.	AF inch	AF mm	Sizes in		Kg
79074	10	1/2	8-10-13-17-18-19-21-22	mm	51053	3

PCS.	Composition	Description	
1	73683	Ratchet	
8	73400, 73402, 73405, 73409, 73410, 73411, 73413, 73414	Sockets	1000V
1	73445	Extension	

12 PCS.

STANDARD

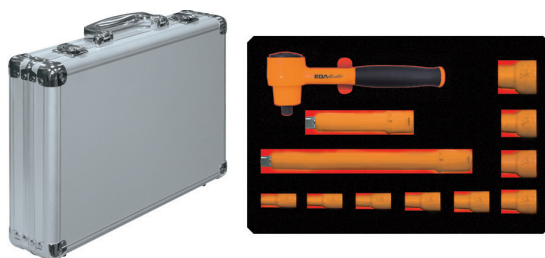

COD.	PCS.	AF inch	AF mm	Sizes in		Kg
79479	12	1/2	1/2-9/16-5/8-11/16-3/4-13/16-7/8-15/16-1	inch	51053	3,2

PCS.	Composition	Description	
1	73683	Ratchet	
2	73445, 73446	Extension	1000V
9	73494, 73495, 73497, 73499, 73500, 73501, 73502, 73503, 75029	Sockets	

14 PCS.


STANDARD



COD.	PCS.	AF inch	AF mm	Sizes in		Kg
79075	14	1/2	8-9-10-11-12-13-14-17-19-21-22-23	mm	51053	3,5

PCS.	Composition	Description	
1	73683	Ratchet	
12	73400, 73401, 73402, 73403, 73404, 73405, 73406, 73409, 73411, 73413, 73414, 74991	Sockets	1000V
1	73445	Extension	

LONG SocketsT

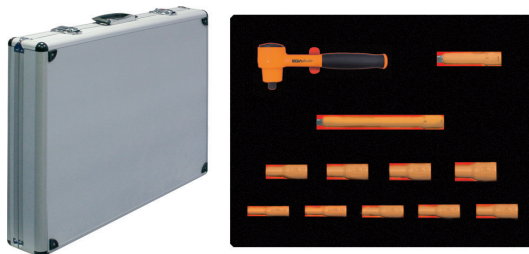


COD.	PCS.	AF inch	AF mm	Sizes in		Kg
79480	12	1/2	1/2-9/16-5/8-11/16-3/4-13/16-7/8-15/16-1 (Long pattern)	inch	51054	6,6

PCS.	Composition	Description	
1	73683	Ratchet	
2	73445, 73446	Extension	1000V
9	75217, 75218, 75219, 75220, 75221, 75222, 75223, 75224, 75225	(L.S.) Sockets	

1/2"

15 PCS.

LONG SocketsT

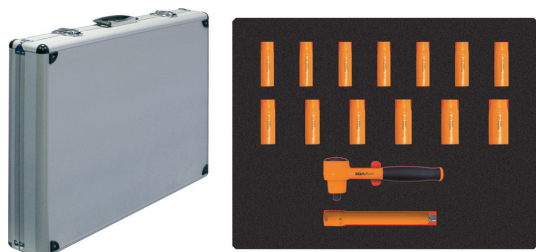


COD.	PCS.	AF inch	AF mm	Sizes in		Kg
79076	15	1/2	10-12-13-14-15-16-17-18-19-21-22-23-27 (Long pattern)	mm	51054	7

PCS.	Composition	Description	
1	73683	Ratchet	
13	75180, 75182, 75183, 75184, 75185, 75186, 75187, 75188, 75189, 75191, 75192, 75193, 75196	(L.S.) Sockets	1000V
1	73446	Extension	

31 PCS.

STANDARD

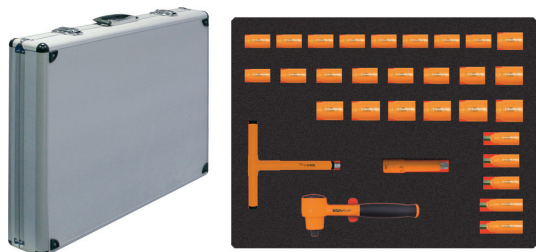

COD.	PCS.	AF inch	AF mm	Sizes in		Kg
79077	31	1/2	8-9-11-12-13-14-15-16-17-18-19-20-21-22-23-24-25-26-27-28-29-30-32	mm	51054	10

PCS.	Composition	Description	
1	73683	Ratchet	
23	73400, 73401, 73403, 73404, 73405, 73406, 73407, 73408, 73409, 73410, 73411, 73412, 73413, 73414, 74991, 73416, 74992, 74993, 73417, 74994, 74995, 73420, 73421	Sockets	1000V
5	73459, 73461, 73463, 73465, 73468	Hexagonal Sockets	8-10-12-14-17 mm - 1000V
1	73445	Extension	1000V
1	73448	T Handle	

18 PCS.

STANDARD



COD.	PCS.	AF inch	AF mm	Sizes in		Kg
73017	18	1/2 - 1/4	6-7 (1/4"); 8-9-10-11-12-13-14-16-17-18-19-21-23	mm	51053	3

PCS.	Composition	Description	
1	73683	Ratchet	
2	73445	Extension	
15	73232, 73233		1000V
15	73400, 73401, 73402, 73403, 73404, 73405, 73406, 73408, 73409, 73410, 73411, 73413, 74991	Sockets	
1	73286	Adapter	1/2"-1/4"

32 PCS.

STANDARD




COD.	PCS.	AF inch	AF mm	Sizes in		Kg
73016	32	1/2	8-9-10-11-12-13-14-15-16-17-18-19-20-21-22-23-24-25-26-27-28-29-30-32	mm	51053	7,3

PCS.	Composition	Description	
1	73683	Ratchet	
1	73445	Extension	
24	73400, 73401, 73402, 73403, 73404, 73405, 73406, 73407, 73408, 73409, 73410, 73411, 73412, 73413, 73414, 74991, 73416, 74992, 74993, 73417, 74994, 74995, 73420, 73421	Sockets	1000V
5	73459, 73461, 73463, 73465, 73468	Hexagonal Sockets	8-10-12-14-17 mm - 1000V

1/2"

37 PCS.

LONG SocketsT

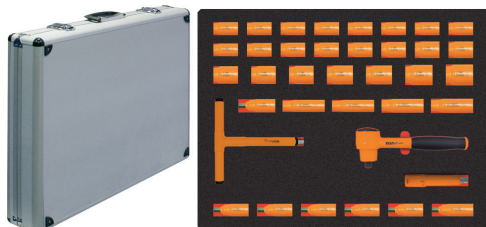

COD.	PCS.	AF inch	AF mm	Sizes in		Kg
79078	37	1/2	8-9-11-12-13-14-15-16-17-18-19-20-21-22-23-24-25-26-27-28-29-30-32 (10-13-17-19 (Long pattern))	mm	51054	10,2

PCS.	Composition	Description	
1	73683	Ratchet	
23	73400, 73401, 73403, 73404, 73405, 73406, 73407, 73408, 73409, 73410, 73411, 73412, 73413, 73414, 74991, 73416, 74992, 74993, 73417, 74994, 74995, 73420, 73421	Sockets	1000V
4	73430, 73433, 73437, 73439	(L.S.) Sockets	
1	73449	Adapter	1/2"-3/8" - 1000V
6	73457, 73459, 73462, 73463, 73464, 73465	Hexagonal Sockets	6-8-11-12-13-14 mm - 1000V
1	73445	Extension	1000V
	73448	T Handle	

