


SIVACON, base, with side cable entry, T: 800 mm, W: 1200 mm, zinc-plated

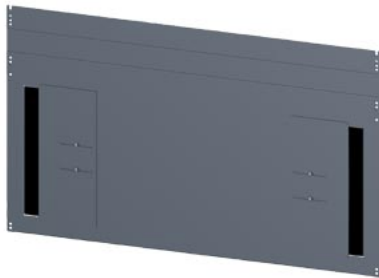

Model	
product brand name	SIVACON
design of the product	With lateral cable entry
design of the surface	zinc plated
design of the product EMC version	No
material	steel
product component	
• ventilation	No

Mechanical Design	
width	1 200 mm
depth	800 mm
net weight	14 000 g


Approvals Certificates

General Product Approval	Test Certificates	other
  	Special Test Certificate	Confirmation Miscellaneous

other	Environment
Miscellaneous	 Environmental Confirmations

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
 Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>
 Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1028-2UB51-2>
 Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/8MF1028-2UB51-2>
 Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1028-2UB51-2
 CAx-Online-Generator
<http://www.siemens.com/cax>
 Tender specifications
<http://www.siemens.com/specifications>

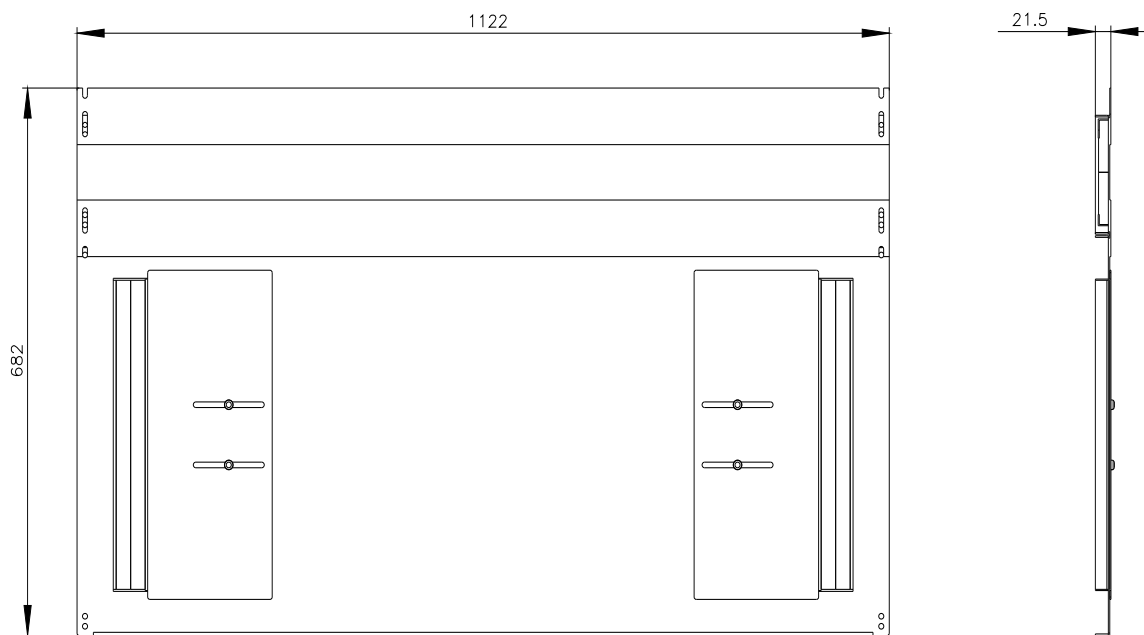

last modified:

6/3/2024 

