


FEATURES

- IP67
- Pre-wired with 100, 200, 300, or 400 mm or customised length cable partially stripped cable
- Front/ screw mounting with M16 thread

RS PRO M12 FEMALE FRONT PANEL MOUNT CONNECTOR 4 PIN 16X1.5 mm THREAD WITH 500 mm TPE CABLE

RS Stock No.: 2080577

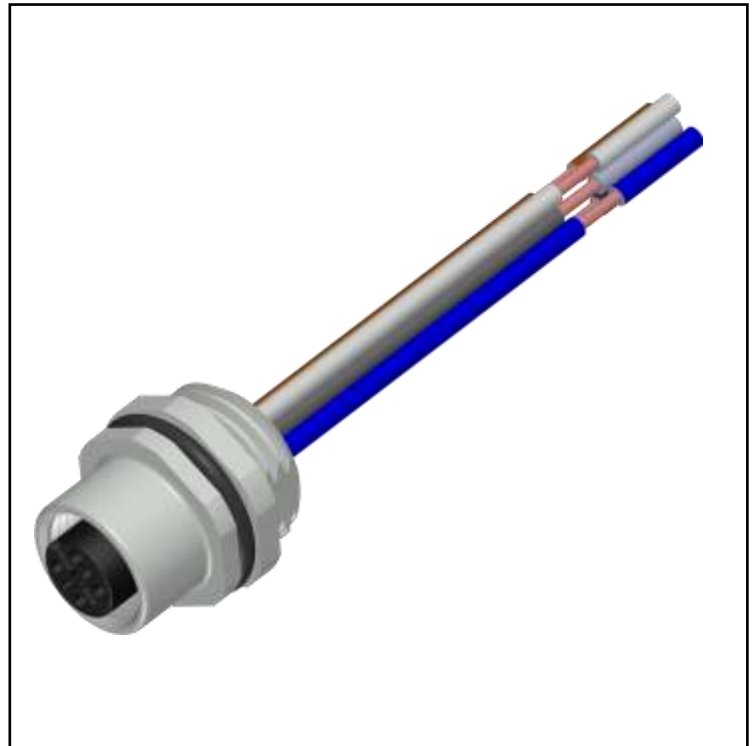

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

ATTRIBUTE 1

M12 Connector M16 Clamp Nut

A series of RS Pro M12 panel-mounted connectors. Each connector within this range is supplied with a partially stripped 100 mm, 200 mm or 300 mm or customised length cable, making it perfect for your application. With IP67 rating and a durable nickel plated brass housing material, each connector is excellent within harsh environments. All models are highly reliable and excellent quality.

Features & Benefits

Contact Plating: Gold plated Supplied with a neoprene O-Ring

Number of poles: 4

Both Female and Male versions available

Applications

The RS PRO series of M12 panel mount connectors are generally used in industrial applications. They are typically used when connecting to sensors and actuators. Some of the most popular areas are

- Instrumentation
- Process control
- Robotics
- Assembly lines
- Factory automation
- Industrial automation

General Specifications

| | |
|---------------------------|-------------------|
| Rated Operational Voltage | 250 V |
| Current Rating | 4A |
| Insulation Resistance | >= 100 MΩ |
| Temperature Range | -25°C ... +75°C |
| Mounting | Front (M16 x 1.5) |
| Coding | A-Coded |

Material Specifications

| | |
|------------------|-----------------|
| Housing Material | Brass Ni Plated |
| Contact | Cu-Zn |
| Contact Plating | Gold Flash |
| Contact Carrier | Nylon 66 |

| | |
|-----------|-----------|
| O-Ring | Neoprene |
| Pole | 4 |
| Clamp Nut | M16 x 1.5 |

Cable Specifications

| | |
|-----------------------|--------------------|
| Cable Length-L | 500 mm |
| Cable Type | 4 Core TPE Cable |
| Cross Section of Wire | 0.34 sq.mm |
| Termination | Partially Stripped |

Protection Category

| | |
|----------------------|------|
| Degree of Protection | IP67 |
|----------------------|------|

Additional Information

| | |
|----------------------|----------|
| Custom Tariff Number | 85369090 |
|----------------------|----------|



Approvals

| | |
|---------------|-----------------|
| Standards Met | IEC 61076-2-101 |
|---------------|-----------------|

Similar Products

| Stock No. | Brand | Product Name | Attribute 1 | Attribute 2 |
|-----------|--------|--|--------------------------------------|-----------------|
| 144-7600 | RS PRO | RS PRO M12 Panel Connector Front 4 Pin 300mm Cable | M12 4 Pin Female Bulk Head Connector | M12 Receptacles |

Connection Diagrams / Assembly Diagrams / Illustrations / Accessories

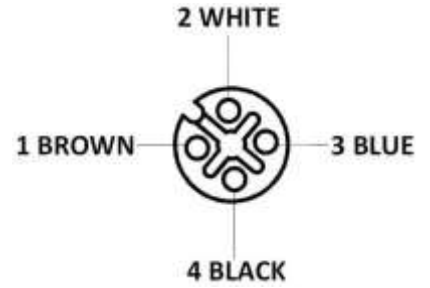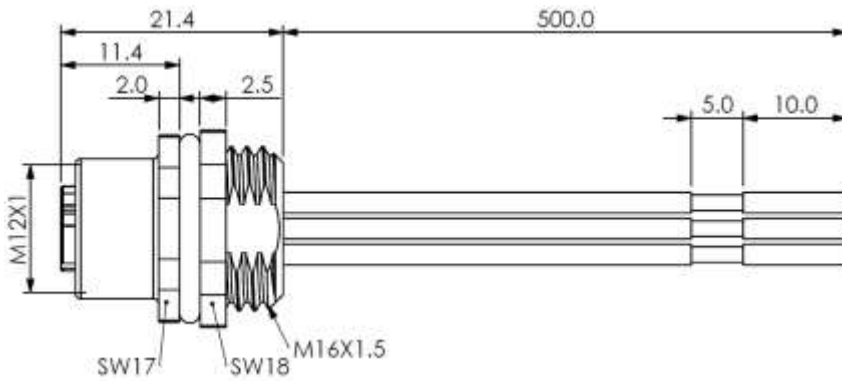

All Dimensions are in mm.

Panel Cutout

