


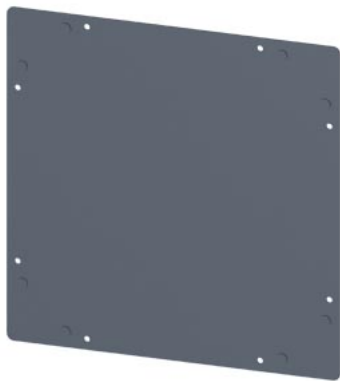

SIVACON, Roof, Closed, IP55, W: 400 mm, T: 400 mm, zinc-plated

Model			
product brand name	SIVACON		
product designation	top plate		
design of the product	Closed		
design of the surface	zinc plated		
design of the product EMC version	No		
Protection class			
protection class IP	IP55		
Suitability			
suitability for use for outside use	No		
Product details			
product component			
● cable entry			No
● ventilation			No
Mechanical Design			
width	400 mm		
depth	400 mm		
material	steel		
Approvals Certificates			
General Product Approval		Test Certificates	other



[Special Test Certificate](#)

[Miscellaneous](#)

[Confirmation](#)

other	Environment
Miscellaneous	Environmental Confirmations

Further information
Information on the packaging https://support.industry.siemens.com/cs/ww/en/view/109813875
Information- and Downloadcenter (Catalogs, Brochures,...) http://www.siemens.com/lowvoltage/catalogs
Industry Mall (Online ordering system) https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1044-2UD11-0A
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1044-2UD11-0A>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1044-2UD11-0A

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

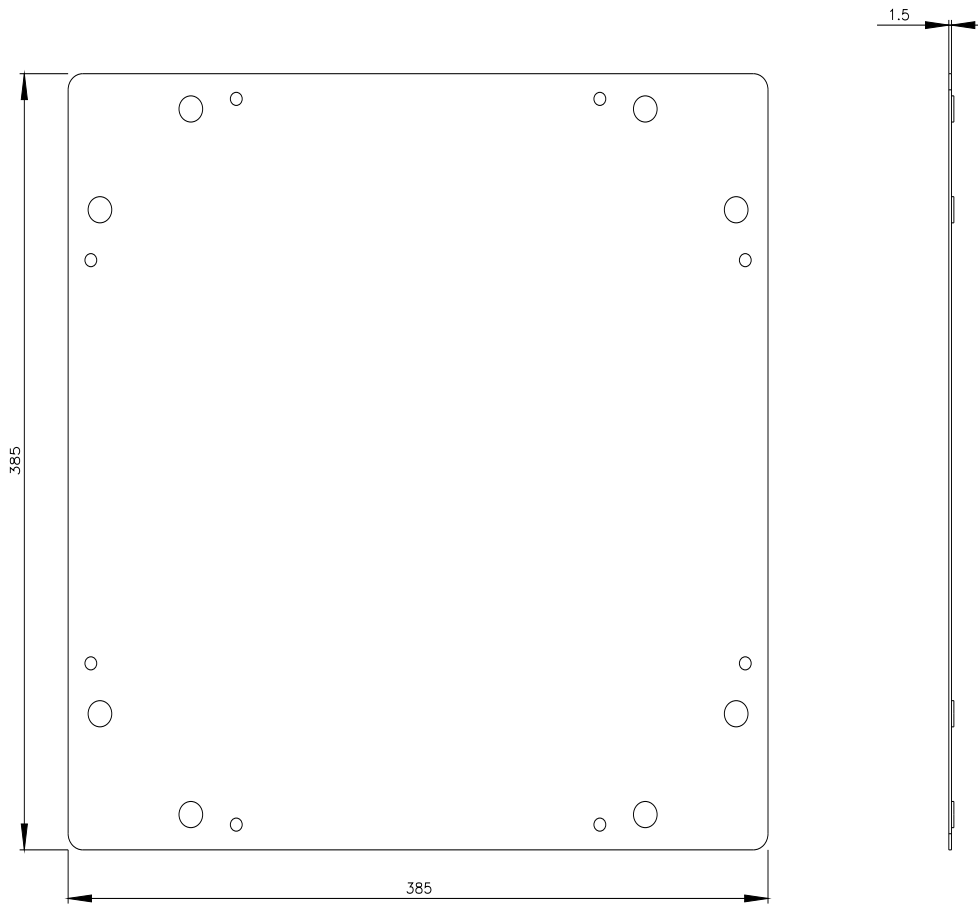

last modified:

7/24/2023 

