


Part Number: [0150390343](#)
Status: Active
Overview: [FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers](#)
Description: 1.00mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 152.00mm Cable Length, Gold (Au) Plating, 18 Circuits

Documents:

図面 (PDF)	Datasheet (PDF)
製品仕様書 PS-15039-001-001 (PDF)	RoHS Certificate of Compliance (PDF)

一般 コメント	Contacts on the same side, Type A
Crimp Quality Equipment 概要	Yes FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
製品名 UPC	Premo-Flex FFC Jumper 193264175222
機械的性能/材質 ケーブル長	152.00mm
極数 (実装)	18
Contact Layout Type	A (same side)
材質 - 嵌合部メッキ	金
梱包形態	ポリ袋
ピッチ - 嵌合部 (インチ)	1.00mm
使用温度範囲	-40° to +105° C
電線サイズ (AWG)	N/A
ケーブル種別	FFC
電気的性能 最大定格電流	1.2A
最大定格電圧	60V AC
参考情報	
図面・仕様書情報	
製品仕様書	PS-15039-001-001
製品図面	SD-15039-001-001

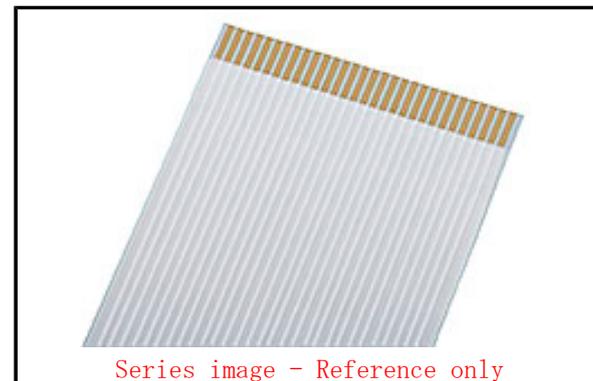

Series image - Reference only

EU ELV
Not Relevant

EU RoHS
Compliant

REACH SVHC
Not Contained Per -
D(2021)10043-DC (17
Jan 2022)

Halogen-Free
Status

Not Low-Halogen
For more information, please visit
[Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[15039 Series](#)

Mates With
Easy-On FFC/FPC Connector:

[522071860](#) , [522711869](#) , [526101872](#) ,
[2005280180](#) , [2005280181](#)