


Datasheet


RS Asymmetric HID Floodlight SONE-I 70 W, IP65, Aluminium

Stock Number - 237-221

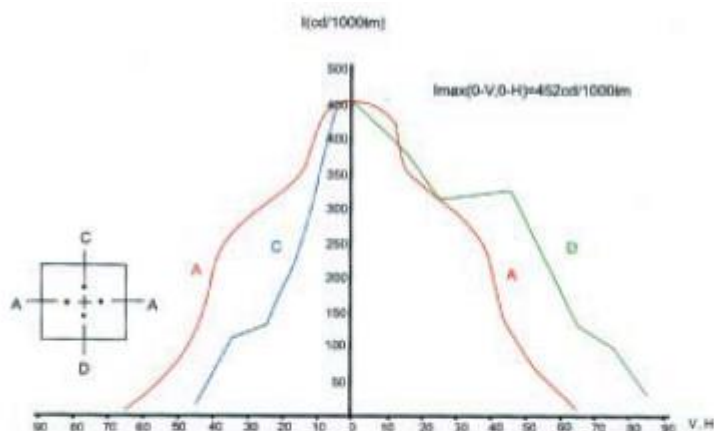

Pressure Sodium to
can be used for
symmetrical reflector

- Die cast aluminium black housing c/w. stirrup bracket
- Designed and manufactured to comply with BS, CE and EN60598
- IP65 rating
- Toughened hinged front glass and aluminium fastening clips
- Integral control gear
- Optional asymmetrical reflector for R x 7's cap (A)

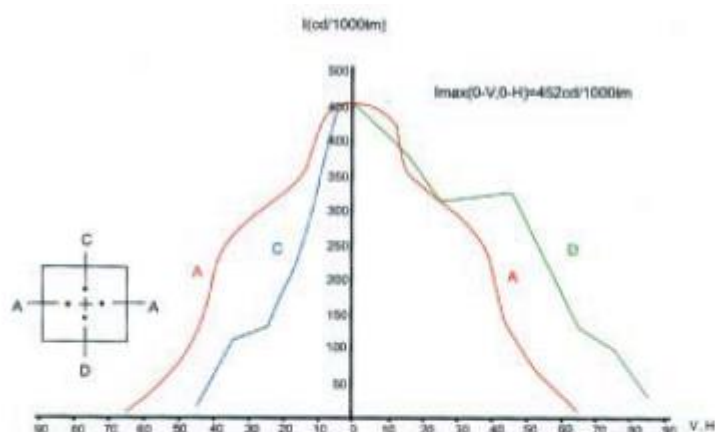

- Die cast aluminium black housing c/w. stirrup bracket
- Designed and manufactured to comply with BS, CE and EN60598
- IP65 rating
- Toughened hinged front glass and aluminium fastening clips
- Integral control gear
- Optional asymmetrical reflector for R x 7's cap (A)

- Optional timed ignitor - H.I.D. only (TI)
- Optional Photo Electric Cell (PC) operating at 70 lux

Description/colour	Box qty	Code
70w. High Pressure Sodium (I), E27	1	TRFLF70HPS (S)
70w. Metal Halide (E), E27	1	TRFLF70MH (S)
150w. Metal Halide (E), E27	1	TRFLF150MH (S)
70w. Metal Halide R x 7's	1	TRFLF70MH (A)
150w. Metal Halide R x 7's	1	TRFLF150MH (A)
70w. CDM, R x 7's	1	TRFLF70CDM (A)
150w. CDM, R x 7's	1	TRFLF7150CDM (A)
80w. Mercury Vapour, E27	1	TRFLF80MV (S)
125w. Mercury Vapour, E27	1	TRFLF125MV (S)

Dimensions:
 Height 387mm
 Width 252mm
 Depth 135mm

Suffix Codes:
 (A) Asymmetrical Reflector
 (P) Projector Reflector
 (PC) Photo Cell
 (S) Symmetrical Reflector
 (TI) Timed Ignitor