



# PRODUCT DATASHEET

Datasheet creation date: 2025/05/28 10:38 (UTC)

MOTION & CONTROL  
**NSK**



## 23040CAME4

### Spherical Roller Bearings

#### Boundary Dimensions


d	200	mm	Bore diameter
D	310	mm	Outside diameter
B	82	mm	Width
r (min.)	2.1	mm	Chamfer dimension

#### Basic Load Ratings

Cr	1180000	N	Basic dynamic load rating
C0r	1700000	N	Basic static load rating

#### Speeds

Thermal Speed Rating (Oil-bath)	1800	min-1	Oil-bath lubrication subject to conditions outlined in ISO 15312
Mechanical (forced-circulation oil)	2400	min-1	Properly designed and controlled forced-circulation oil lubrication
Grease	1000	min-1	Grease lubrication
Oil (Oil-bath)	1300	min-1	Oil-bath lubrication

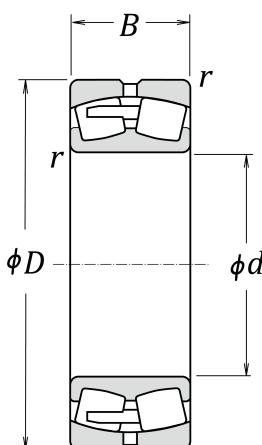

#### Abutment and Fillet Dimensions

da (min.)	212	mm	Diameter of shaft abutment
Da (min.)	279	mm	Diameter of housing abutment
Da (max.)	298	mm	Diameter of housing abutment
ra (max.)	2	mm	Radius of shaft or housing fillet

#### Calculation factors

e	0.25	Constant
Y2	4	Axial load Factors
Y3	2.7	Axial load Factors
Y0	2.6	Axial load Factors

#### Mass

Mass approx.	22.6	kg	Mass approx.
--------------	------	----	--------------

