

# UM-ALU 4 AU45 L990 - Profile cover



2200961

<https://www.phoenixcontact.com/gb/products/2200961>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Press-drawn section housings, Screw mounting, Profile cover, width: 45.6 mm, profile width (internal): 42 mm, profile width (external): 45.6 mm, length: 990 mm, depth: 28.1 mm

## Your advantages

- Aluminum extruded profile
- Variety of connection technology
- Can be mounted on the DIN rail
- Available in lengths from 42.5 mm ... 990 mm, can be cut to any length
- Available in overall widths of 75 mm and 105 mm
- EMC protection

## Commercial data

|                                      |                     |
|--------------------------------------|---------------------|
| Item number                          | 2200961             |
| Packing unit                         | 1 pc                |
| Minimum order quantity               | 1 pc                |
| Sales key                            | ACHDFC              |
| Product key                          | ACHDFC              |
| Catalog page                         | Page 264 (NTK-2012) |
| GTIN                                 | 4046356721035       |
| Weight per piece (including packing) | 531 g               |
| Weight per piece (excluding packing) | 531 g               |
| Customs tariff number                | 76042990            |
| Country of origin                    | DE                  |

# UM-ALU 4 AU45 L990 - Profile cover



2200961


<https://www.phoenixcontact.com/gb/products/2200961>

## Technical data

### Product properties

|                              |                              |
|------------------------------|------------------------------|
| Product type                 | Component housing cover      |
| Housing type                 | Press-drawn section housings |
| Housing series               | UM-ALU                       |
| Product family               | UM-ALU                       |
| Type                         | Profile cover                |
| Ventilation openings present | no                           |

### Dimensions
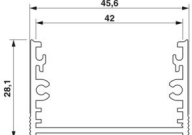
|                     |  |
|---------------------|--|
| Dimensional drawing |  |
| Width               | 45.6 mm  |
| Depth               | 28.1 mm  |
| Length              | 990 mm   |

### External dimensions

|                          |         |
|--------------------------|---------|
| Profile width (external) | 45.6 mm |
|--------------------------|---------|

### Internal dimensions

|                          |       |
|--------------------------|-------|
| Profile width (internal) | 42 mm |
|--------------------------|-------|

### PCB design

|               |                  |
|---------------|------------------|
| PCB thickness | 1.44 mm ... 2 mm |
|---------------|------------------|

### Material specifications

|                         |                |
|-------------------------|----------------|
| Color (Housing)         | Aluminum color |
| Housing material        | Aluminum       |
| Surface characteristics | anodized       |

### Environmental and real-life conditions

#### Ambient conditions

|   |  |
|---|--|
| Max. IP code to attain                  | IP40   |
| Ambient temperature (operation)         | -40 °C ... 100 °C (depending on power dissipation) |
| Ambient temperature (storage/transport) | -40 °C ... 55 °C                                   |
| Ambient temperature (assembly)          | -5 °C ... 100 °C                                   |

### PCB data

|                       |      |
|-----------------------|------|
| Number of PCB holders | 4    |
| Type of PCB mount     | Slot |

# UM-ALU 4 AU45 L990 - Profile cover



2200961

<https://www.phoenixcontact.com/gb/products/2200961>

|                      |   |
|----------------------|---|
| PCB surface          | 27215 mm <sup>2</sup> ... 38191 mm <sup>2</sup> (TOP in conjunction with side elements COVERLID...AL or 4LID...PA)    |
|                      | 27049 mm <sup>2</sup> ... 37201 mm <sup>2</sup> (BOTTOM in conjunction with side elements COVERLID...AL or 4LID...PA) |
| Thickness of the PCB | 1.44 mm ... 2 mm  |

## Mounting

|                   |                          |
|-------------------|--------------------------|
| Mounting type     | Screw mounting           |
| Mounting position | parallel to the DIN rail |

## Packaging specifications

|                      |                     |
|----------------------|---------------------|
| Type of packaging    | packed in cardboard |
| Outer packaging type | Carton              |

# UM-ALU 4 AU45 L990 - Profile cover


2200961

<https://www.phoenixcontact.com/gb/products/2200961>



## Drawings

Schematic diagram

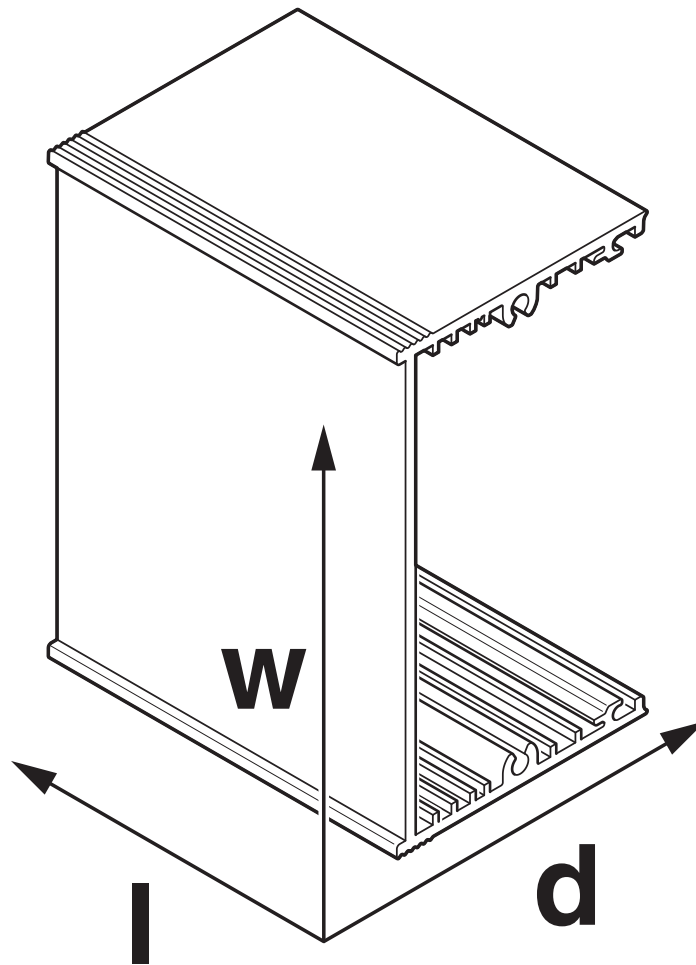


# UM-ALU 4 AU45 L990 - Profile cover

2200961

<https://www.phoenixcontact.com/gb/products/2200961>



Dimensional drawing

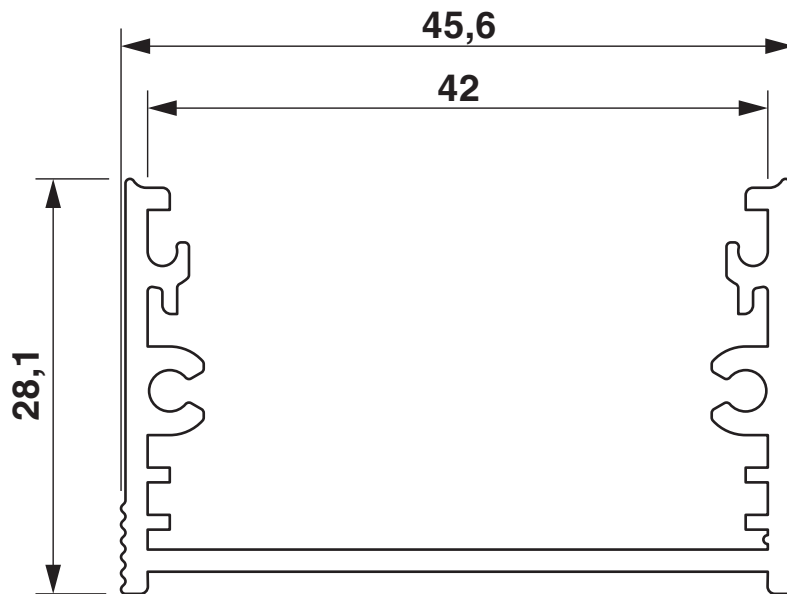

# UM-ALU 4 AU45 L990 - Profile cover



2200961

<https://www.phoenixcontact.com/gb/products/2200961>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-11.0 | 27182701 |
| ECLASS-13.0 | 27190603 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC002779 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

# UM-ALU 4 AU45 L990 - Profile cover



2200961

<https://www.phoenixcontact.com/gb/products/2200961>

## Environmental product compliance

|   |  |
|---|--|
| EU RoHS                                 |  |
| Fulfills EU RoHS substance requirements | Yes, No exemptions                       |
| China RoHS                              |  |
| Environment friendly use period (EFUP)  | EFUP-E                                   |
|   | No hazardous substances above the limits |
| EU REACH SVHC                           |  |
| REACH candidate substance (CAS No.)     | No substance above 0.1 wt%               |

Phoenix Contact 2024 © - all rights reserved  
<https://www.phoenixcontact.com>

PHOENIX CONTACT Ltd  
Halesfield 13, Telford  
Shropshire, TF7 4PG  
01952 681700  
[info@phoenixcontact.co.uk](mailto:info@phoenixcontact.co.uk)