

Mini Smart Wi-Fi Socket

Tapo P100



Remote Control



Auto-Off Timer



Voice Control



Easy Setup



Set schedules



Away Mode



Flame-Retardant




Share to Family



// Highlights


Remote Control from Anywhere

Instantly turn connected devices on/off wherever you are via the Tapo app. Designed to facilitate your life and keep your family safe.

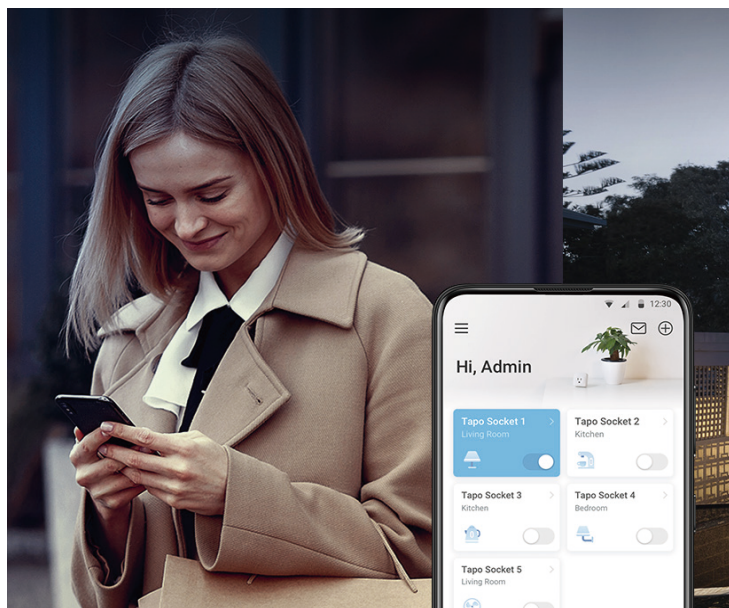

Schedule and Auto-Off Timer


Create weekly schedule and countdown plans. All of your connected electronics will automatically work at your preset time, making your life smart, convenient, and energy-saving.

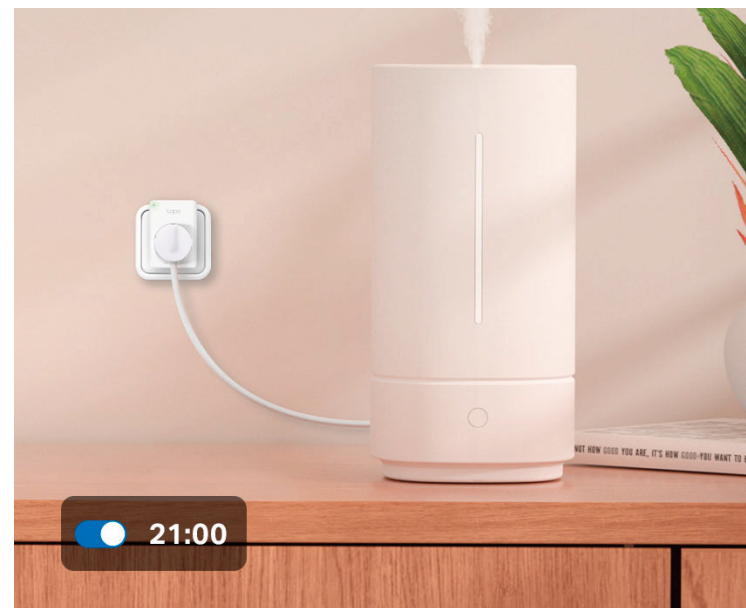

// Highlights


Safety First

Has undergone rigorous quality inspections to receive CE certification. It uses premium UL94-V0 materials, flame retardant up to 750 °C.

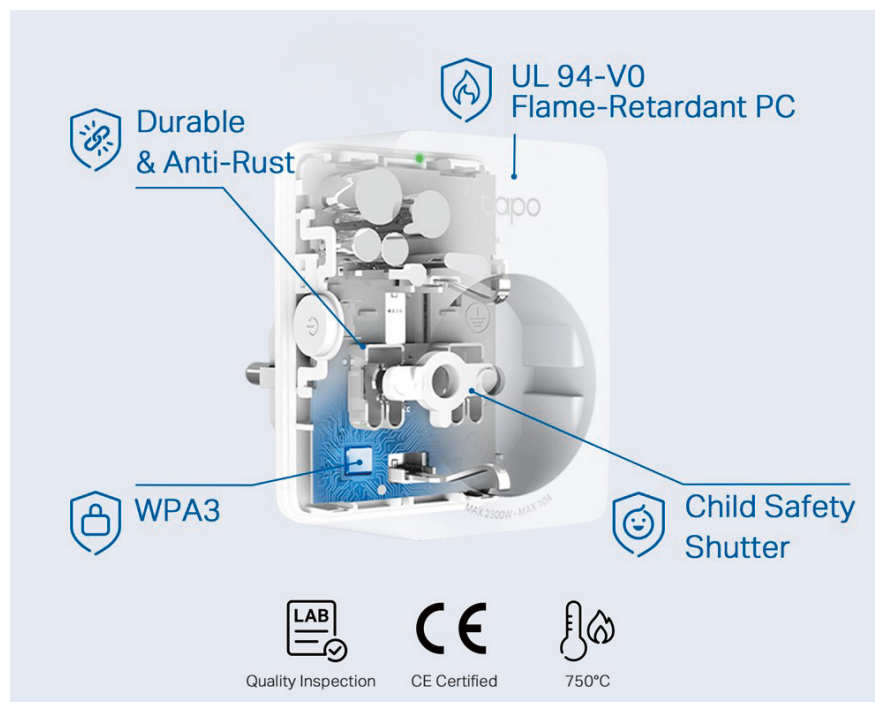

Voice Control

Use simple voice control with Alexa and Google Assistant to conveniently control connected devices without leaving your spot.

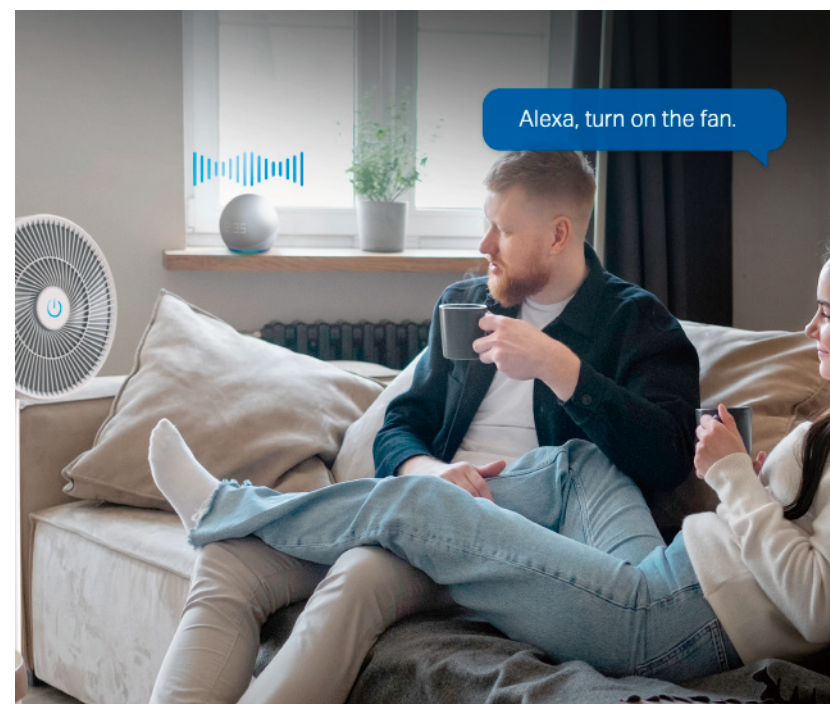

// Features

- **Remote Control** – Instantly turn connected devices on/off wherever you are through the Tapo app.
- **Schedule** – Preset a schedule to automatically manage devices.
- **Timer** – Create a countdown timer for connected electronics.
- **Voice Control** – Manage your smart plug with voice commands via Amazon Alexa or the Google Assistant.
- **Away Mode** – Automatically turns devices on and off at different times to give the appearance that someone is home.
- **Compact Design** – Mini-sized to avoid blocking adjacent plugs.
- **Easy Setup and Use** – No hub required, set up quickly and manage easily through the free app.
- **Device Sharing** – Easily share management permissions with each member of your family.
- **Flame-Retardant*** – PC flame-retardant materials help minimize burning hazards.

*Made with V-0 (UL94) flame-retardant materials.

// Specifications

General

- LED&Button: Status LED, Switch Button
- Material: V-0(UL-94) Flame retardant PC
- Protocols: IEEE 802.11b/g/n, 2.4 GHz Wi-Fi
- Onboarding: Bluetooth 4.2[†]
- Voltage: AC, 100-240 V, 50/60 Hz
- Max Load: 2,300 W, 10 A[‡]
- Networked Standby Power Consumption: 1.90 W
- All Network Ports Connected Power Consumption: 1.90 W

Status LED

Switch Button



Socket Plug



Wireless

- Wireless Standards: IEEE 802.11b, 802.11g, 802.11n
- Frequency: 2.400-2.4835 GHz
- Signal Rate: 72 Mbps at 2.4 GHz
- Transmit Power: < 20 dBm (EIRP)
- Wireless Function: Wireless Client
- Wireless Security: No Security; WPA-PSK; WPA2-PSK; WPA3

Others

- Package Contents:
Mini Smart Wi-Fi Socket Tapo P100
Quick Start Guide
- Certifications: CE, EAC, RoHS
- Operating Temperature: 0 °C–40 °C
- Operating Humidity: 10%–90%RH, Non-condensing
- Dimensions: 72 × 51 × 40 mm

Classification of switch integrated in this product:

- Pollution Degree: 2
- Rated Impulse withstand Voltage: 2500 V
- Level of resistance to fire with est according to glow wire temperature: 750 °C
- Number of Operating Cycles: 10000

[†]Bluetooth is only used for onboarding.

[‡]The total power of the connected electrical equipment should not exceed the max load current, and maximum power supported varies based on the appliance.

Please do not use in damp environments or outdoors. For more information, please visit <https://www.tapo.com/>

Specifications are subject to change without notice. All brands and product names are trademarks or registered trademarks of their respective holders.

©2024 TP-Link