


Film, Metallized Polypropylene, DC Link, C4DE, 380 uF, 10%, 400 V

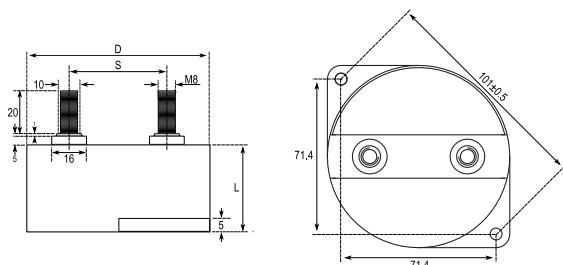

Dimensions

D	84mm +/-0.5mm
L	64mm +/-2mm
S	45mm +/-1mm
LL	20mm NOM

Packaging Specifications

Mounting:	Flange Mount
Packaging:	Bulk
Packaging Quantity:	12

General Information

Dielectric:	Metallized Polypropylene
Style:	Can
Series:	C4DE
RoHS:	Yes
Lead:	Threaded Studs M8
Miscellaneous:	42 Amps (10kHz, 85C)

Specifications

Capacitance:	380 uF
Capacitance Tolerance:	10%
Voltage DC:	400 VDC
Temperature Range:	-40/+85C
Rated Temperature:	85C
Max dVdt:	15 V
Resistance:	0.81 mOhms (10kHz)
Current:	100 Amps (10kHz 25C), 94 Amps (10kHz 45C), 73 Amps (10kHz 65C)
Inductance:	40 nH