



Brand of NTN corporation

Technical data

UCFC207

Bearing units




Grey cast housing, radial insert ball bearing with socket set screws, seal with slinger

KIT CONTENT

UC207G2, FC207

VISUAL (S)

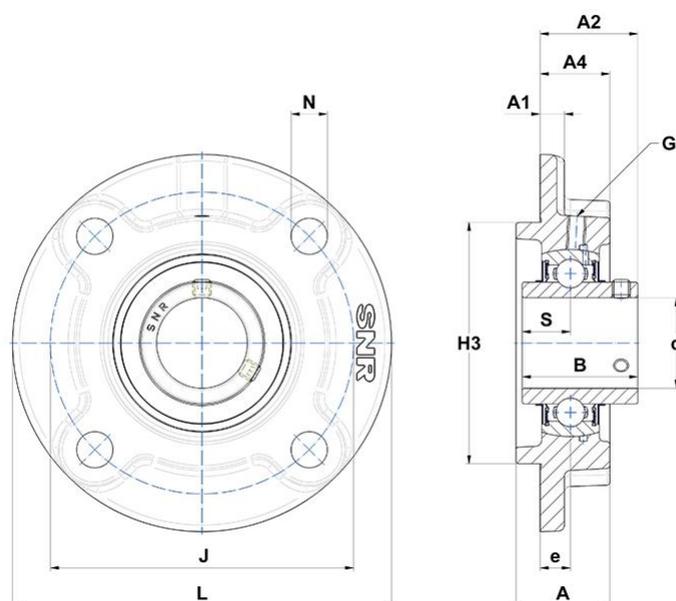

PRODUCT DEFINITION

Brand	SNR
A - Housing height	34 mm
A1 - Housing foot height / flange height	9 mm
A2 - Total height from mounting surface	36,4 mm
A4 - Housing height from mounting surface	26 mm
B - Width of Inner Ring	42,9 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

d - Shaft diameter	35 mm
e - Distance mounting surface to bearing center	11 mm
G - Grease fitting	M6x1
H3 - Centering dia	90 mm
J - Mounting holes distance	110 mm
L - Housing width / diameter	135 mm
N - Mounting hole dimension	14 mm
S - Distance front side/bearing centre	17,5 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	25700000 mN
C0 - Static load rating	15200000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	1,66 kg
Recommended tightening torque for set screw	11.5 N-m

